


BZH15/Z0000/70 Datasheet

 [View Product Page](#)

Product Name // Horizontal Power Entry Module 74.5mm
C14 Cold Condition Inlet Integral Twin Fused (PF0033)
6.3mm Tab Termination Unfiltered Double Contact Switch
Marked I/O

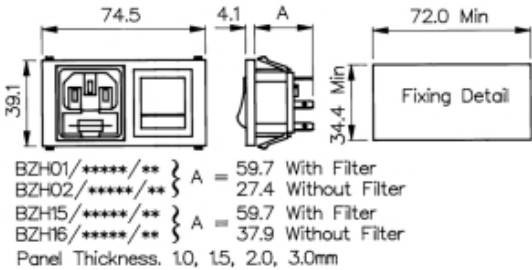

// Product Description:

- Horizontal Power Entry Module 62.7mm/74.5mm
- C14 Cold Condition Inlet with integral fuseholder(s) depending on part code:
- Part codes prefixed BZH01, BZH02: PF0011 Single Fused Inlet
- Part codes prefixed BZH15, BZH16: PF0033 Twin Fused Inlet
- Choice of Termination depending on part code:
- Part codes prefixed BZH01, BZH15: 6.3mm Tab
- Part codes prefixed BZH02, BZH16: 2.8mm Tab
- Choice of mains filter depending on part code:
- Part codes containing /Z0000 are unfiltered
- Choice of mains filter options (part codes containing codes starting /A)
- Choice of many other options as specified by individual part code, including indicators, illuminated switches, switch markings, etc

// General Information:

Product Display Title:	Horizontal Power Entry Module 62.7mm/74.5mm
Product Family:	IEC Connectors
Product Series:	Power Entry Modules
Current Max:	10A
Filter Type:	Unfiltered
Function:	C14 Inlets
Fuseholder Inlet Type:	Integral Twin Fused
Iec Connector Components:	None
Iec Connector Mates With:	PF0033
Iec Filter Options:	Unfiltered
Iec Horizontal Module Width:	74.5mm
Inlet Type:	C14 Cold Condition Inlet
Switch Type:	Double Contact Marked I/O
Voltage Max:	250V

// Product PDF Links

 [Power Entry Modules product data](#)

// Product 3D CAD Model Links

 [BZH15/Z0000/703D CAD Model](#)