


SLIM LED FLOODLIGHT ORLANDO

ORLANDO90G

90 W - 9900lm - 4000K

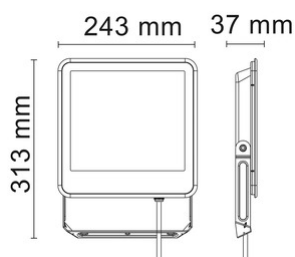

DIMENSIONS	A	B	C
1	313	---	37

GENERAL INFORMATIONS	
Code	ORLANDO90G
Ean	8031453023294
Family	SLIM LED FLOODLIGHT ORLANDO
Technology	LED
Body material	Aluminum
Diffuser / lens material	Glass
Operating temperature (° C)	-20 - +40

PACKAGING	
Packaging	BOX
Pack	5

LIGHTING DATA	
Kelvin (°)	4000
Lumen	9900
Beam (°)	110
Luminous efficacy (lm / W)	110
Color rendering (CRI)	>70

TECHNICAL FEATURES	
Power (W)	90
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50/60
Insulation class	1
Power factor	>0,9
Dimmer compatibility	NO

SLIM LED FLOODLIGHT ORLANDO

ORLANDO90G

90W - 9900lm - 4000K

- Slim LED floodlight with 'Driver On Board' (DOB) technology
- High efficiency 110 lm / W (ORLANDO10B/G 90 lm/W)
- Painted aluminum body with tempered glass diffuser
- White RAL 9016 or grey RAL 7024 colors - PIR version only in grey RAL 7024
- ORLANDO90B/G: Integrated valve to in order to avoid condensation

