


# Common supply manifold VABM-B10-20-N38-6-P53

Part number: 576379

FESTO

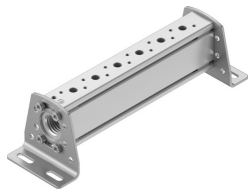

 [General operating condition](#)

## Data sheet

| Feature                        | Value                         |
|--------------------------------|-------------------------------|
| Grid dimension                 | 22 mm                         |
| Mounting position              | optional                      |
| Max. number of valve positions | 6                             |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L             |
| Product weight                 | 395 g                         |
| Type of mounting               | Via mounting bracket          |
| Pneumatic connection, port 1   | 3/8 NPT                       |
| Note on materials              | RoHS-compliant                |
| Material manifold rail         | Wrought aluminium alloy       |