




Part Number : [151660317](#)

Product Description : 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 51.00mm Cable Length, Tin (Sn) Plating, 30 Circuits

Series Number : 15166

Status : Active

Product Category : Flat-Flexible Cable (FFC)

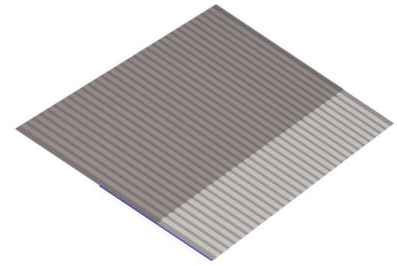

Documents & Resources

Drawings

[151660317 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-15166-001-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Not Relevant |
| China RoHS | per SJ/T 11365-2006  |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2025)4165-DC (25 June 2025) |
| EU RoHS | Compliant per EU 2015/863 |

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

[Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|--|
| Status | Active |
| Category | Flat-Flexible Cable (FFC) |
| Series | 15166 |
| Description | 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 51.00mm Cable Length, Tin (Sn) Plating, 30 Circuits |
| Comments | Contacts on the same side, Type A |
| Product Name | Premo-Flex FFC Jumper |
| UPC | 884982848153 |

Electrical

| | |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum | 60V AC |

Physical

| | |
|---------------------------|----------------|
| Cable Length | 51.00mm |
| Circuits (Loaded) | 30 |
| Contact Layout Type | A (same side) |
| Design Feature | Ultra-Flexible |
| Material - Plating Mating | Tin |
| Net Weight | 1.000/g |
| Packaging Type | Bag |
| Pitch - Mating Interface | 0.50mm |

| | |
|-------------------------------|-----------------|
| Temperature Range - Operating | -40° to +105°C |
| Termination Style | FFC Connector |
| Wire/Cable Type | Flat Flex Cable |
| Wire Size (AWG) | N/A |

Mates With / Use With

Mates with Part(s)

| Description | Part Number |
|--|-----------------------------------|
| Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 30 Circuits, Copper Alloy, Tin-Bismuth Plating | <u>5019513000</u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating | <u>524353072</u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating | <u>524373072</u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating | <u>541043096</u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating | <u>541323097</u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 30 Circuits, Tin-Bismuth Plating | <u>525593072</u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard | <u>781193010</u> |

| | |
|---|------------------|
| Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 30 Circuits | |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 30 Circuits | <u>781273010</u> |