

# DIECAST AND METAL BOXES

## 5000 Series Multi-Purpose Diecast




Highly durable robust aluminium diecast boxes with RFI shielding properties.

- Diecast aluminium
- Lid mounted by four M3 machine screws
- Temperature resistant up to 260°C (without gasket)
- Highly Durable and shock resistant
- Vertical guides for PCB fixing
- Optional neoprene gasket for IP65 seal

### SPECIFICATION

Materials	Lid & base diecast aluminium to ENAC 44200
Protection class	IP62 IP65 optional
Standard colours	Black RAL 9004, white RAL 9010, natural or hammertone Powder coating optional
Standard unit includes	Base, lid & x4 zinc plated M3 screw
Options	Wall mounting kit IP65 gasket

NATURAL	HAMMERTONE	BLACK	WHITE	LENGTH	WIDTH	HEIGHT
RTM5001/11-NAT	RTM5001/11-PAT	RTM5001/11 - BLK	RTM5001/11 - WH	50mm	50mm	31mm
RTM5002/12-NAT	RTM5002/12-PAT	RTM5002/12 - BLK	RTM5002/12 - WH	101mm	50mm	25mm
RTM5003/13-NAT	RTM5003/13-PAT	RTM5003/13 - BLK	RTM5003/13 - WH	112mm	62mm	31mm
RTM5004/14-NAT	RTM5004/14-PAT	RTM5004/14 - BLK	RTM5004/14 - WH	120mm	66mm	40mm
RTM5005/15-NAT	RTM5005/15-PAT	RTM5005/15 - BLK	RTM5005/15 - WH	152mm	82mm	50mm
RTM5006/16-NAT	RTM5006/16-PAT	RTM5006/16 - BLK	RTM5006/16 - WH	192mm	112mm	61mm
RTM5007/17-NAT	RTM5007/17-PAT	RTM5007/17 - BLK	RTM5007/17 - WH	121mm	95mm	61mm

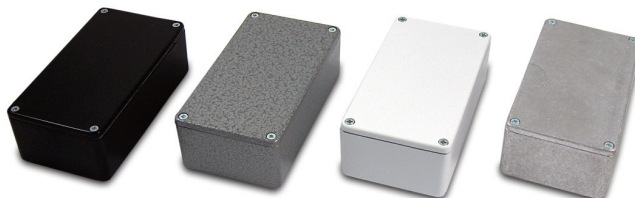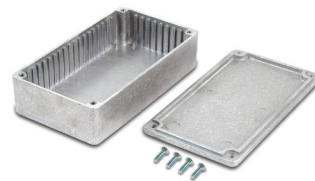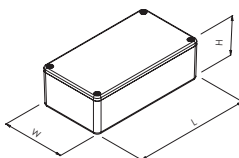

### Wall mounting kit

- One type fits all sizes



### TYPE NO.

### DESCRIPTION

5000-KIT	Wall mounting kit
----------	-------------------

### 5000-IP Gasket

- Neoprene gasket, 1.5mm thick
- Resistant to acids, gasoline
- Suitable for outdoor applications
- Protection rating IP 65



### TYPE NO.

### DESCRIPTION

FT094-517	5001-11 Gasket
FT094-505	5002-12 Gasket
FT094-509	5003-13 Gasket
FT094-510	5004-14 Gasket
FT094-513	5005-15 Gasket
FT094-506	5006-16 Gasket