

Features

- High precision tweezers with straight, fine and pointed tips.
- Suitable to applications which require holding a component firmly while granting good visibility.
- The short body allows a firmer grip combined with greater practicality.
- Anti-magnetic Anti-Acid Stainless Steel (SA).
- Laser marking.
- MADE IN ITALY.

RS PRO High precision tweezers. MADE IN ITALY.

RS Stock No.: (0845444)



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description



High Precision tweezers are the ideal instruments to hold a component firmly while granting a good visibility and to handle, grab or hold small objects when precision and accuracy is needed. Typical applications include different tasks in microelectronics, jewellery making, laboratory, watch making and repairs, DIY and medical fields in mild aggressive chemical environments.

General Specifications


Point Type	Straight, fine and pointed
Overall length (mm)	110
Overall length (")	4.331"
Tweezers width (mm)	9.5 (0.374")
Tweezers height (mm)	10.0 (0.394")
Tip width (mm)	0.40 (0.016")
Tip thickness (mm)	0.25 (0.010")
Net weight	11.6 g
Version	SA
Type of material	Low carbon austenitic Steel
Anti-magnetic	Yes
Anti-acid	Yes



TIP DETAILS:

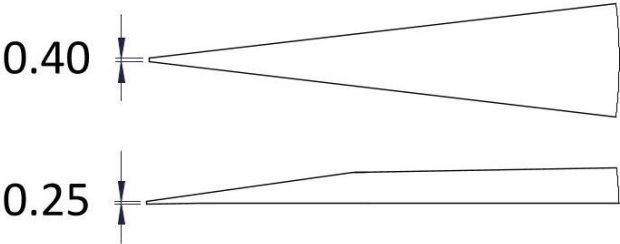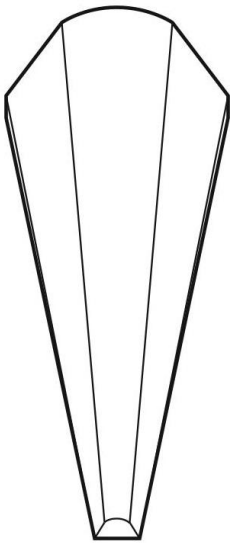

Dimensions mm

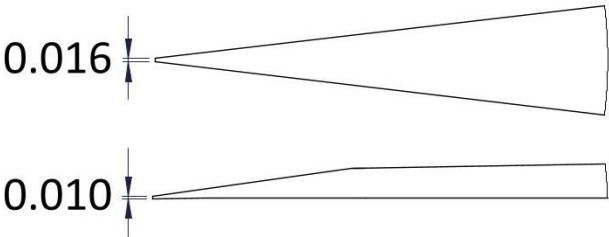

Dimensions inch