

SylSpot Kit


SYLSPOT KIT ROUND 345LM 830 ADJ IP20 CHR

0005728



Product features

- Recessed spotlight Kit with RefLED GU10 LED spotlight lamp Ø50mm. Polycarbonate body, round bezel ring in chrome finish, vertical tilt 25°, IP20 degree of protection, class II. Lumen output 345lm, CCT 3000K, beam angle 36°, power 4,5W, efficacy 77 lm/W, lifetime 15.000h. Outer dimensions: Ø80x90mm, cut-out Ø68-76mm. Suitable for internal environment only and for LED lamps only.

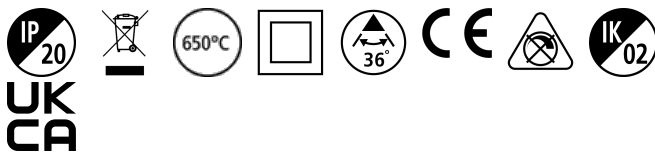

PRODUCT OVERVIEW

IPC Code	0005728
Product name	SYLSPOT KIT ROUND 345LM 830 ADJ IP20 CHR
Technology	LED (replaceable lamp)
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
ETIM Class	EC001744
Fixture luminous flux (lm)	345
Luminaire efficacy (lm/W)	77
Colour temperature (K)	3000
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	36
Photobiological Risk Group	RG1
Total power consumption (W)	4.5
Electrical protection	Class II
Dimmable	No
Housing colour	Chrome
IP rating	IP20
IK rating	IK02
Product EAN number	5410288057286
Included lamp	0028433

DATA TABLE

General data

IPC Code	0005728
Product name	SYLSPOT KIT ROUND 345LM 830 ADJ IP20 CHR
Technology	LED (replaceable lamp)
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting

SylSpot Kit

SYLSPOT KIT ROUND 345LM 830 ADJ IP20 CHR
0005728

Environment	Indoor
General application	Residential & Consumer
ETIM Class	EC001744

Optical data

Fixture luminous flux (lm)	345
Luminaire efficacy (lm/W)	77
Colour temperature (K)	3000
Colour Code	830
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	36
Photobiological Risk Group	RG1

Electrical data

Total power consumption (W)	4.5
Mains voltage (V)	220-240V~
Electrical protection	Class II
Dimmable	No
Inrush Current (A)	10
Inrush Duration (µs)	150
Glow Wire Test (°C)	650
Nominal Frequency (Hz)	50/60Hz
Max. Luminaires per 10A C Breaker	100
Max. Luminaires per 13A C Breaker	130
Max. Luminaires per 16A C Breaker	160
Max. Luminaires per 20A C Breaker	200

Lifetime data

Lifespan - L70 B50	15000
--------------------	-------

Physical data

Housing colour	Chrome
IP rating	IP20
IK rating	IK02
Nominal Product Length (mm)	90
Nominal Product Width (mm)	90
Nominal Product Height (mm)	85
Nominal Product Diameter (mm)	90
Weight (kg)	0.09

Packaging



Single packaging type	Carton
Product EAN number	5410288057286
Packaging single length / height (cm)	9.0
Packaging single width (cm)	7.0
Packaging single depth (cm)	11.5
DUN14 (outer)	15410288057283

SylSpot Kit


SYLSPOT KIT ROUND 345LM 830 ADJ IP20 CHR
0005728

Units per outer package	48
Packaging outer length / height (cm)	46.8
Packaging outer width (cm)	40.0
Packaging outer depth (cm)	29.1

PHOTOMETRY

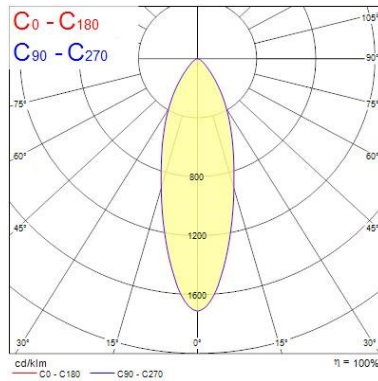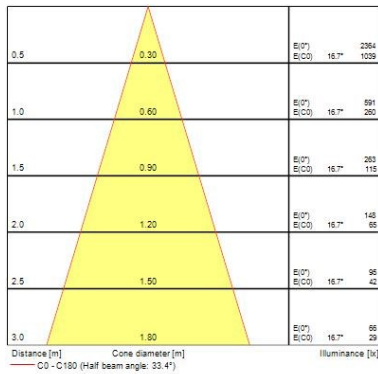

TECHNICAL DRAWINGS

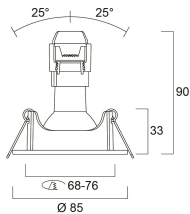

SylSpot Kit

SYLSPOT KIT ROUND 345LM 830 ADJ IP20 CHR
0005728


SYLVANIA 0005728


 Valaisimessa voidaan käyttää seuraaviin energialuokkiin kuuluvia energialuokkiin kuuluvia





Valaisimen mukana toimitettavan lampun energialuokka: 

874/2012 

 Valaisimessa voidaan käyttää seuraaviin energialuokkiin kuuluvia energialuokkiin kuuluvia

Valaisimen mukana toimitettavan lampun energialuokka: 

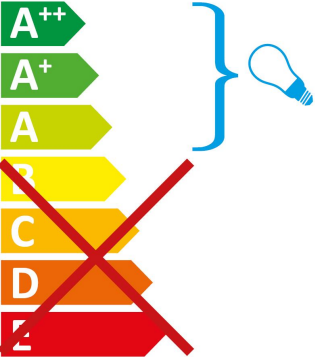

SYLVANIA 0005728 

874/2012