


Metal Binding Posts

- Post heads are nickel plated brass.
- Bodies are machined brass with tin plating.
- Connects with .080" phone tip plug, 1/4" spade lug, standard banana plug, alligator clip or wire (to #14).
- To connect circuit, wrap wire around solder turret or attach to solder lug between nuts (lug not supplied).
- Please refer to Table A (page 12) for post rating information.


PART NO.	FIG.	MNTG. HOLE	POST THREAD	HEAD SHAPE
1835	A	1/2 "D"	10-32	Hex
137	B	#8	8-32	

Abbatron Binding Posts Safety Features:


- Insulating material is high-temperature, flame-retardant polycarbonate, with a UL continuous-usage temperature of 220°F (110°C), and UL Flammability Rating of 94 V-O.
- Restricted head-opening prevents contact with live metal parts, even with the head screwed back down. Positive internal captivation does not allow the head to be removed, even with excessive torque.
- Recessed and insulated banana jack opening will not allow contact with the metal stud, even with the head screwed down. Abbatron recommends using the 289 style shrouded banana plug for the highest possible safety level.
- Positive, double-keyed insulating washers prevent rotation of the stud or body when tightened into a keyed panel hole.

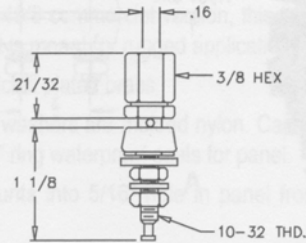

A

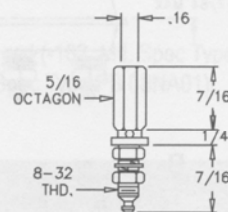

B

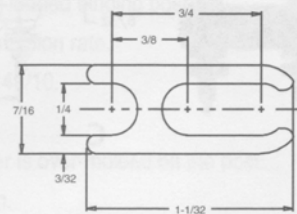

1828

Shorting Link:

- Constructed of spring brass with nickel plating.
- Rated at 20 Amps.
- Fits 269 style posts (page 16).