



E-Z-PICO-HOOK™ TEST LEADS

 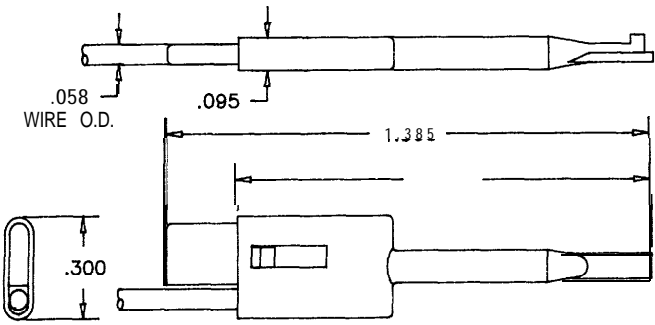


The E-Z PICO-HOOK is designed specifically for narrow test contact access. illustrated by integrated circuit in-line pins. An ultra-thin blade and housing allows connector stacking and easier access.

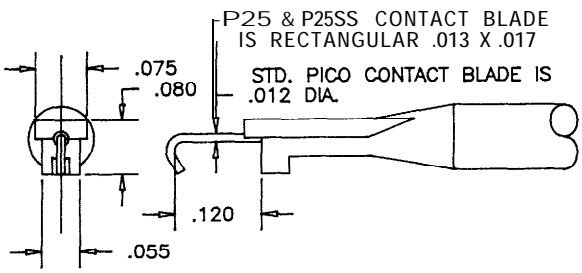


EXTENDED HOOK DETAIL

SCALE 4X FULL SIZE
ALL DIMENSIONS ARE IN INCHES



ACTUAL SIZE

Patent Applied for

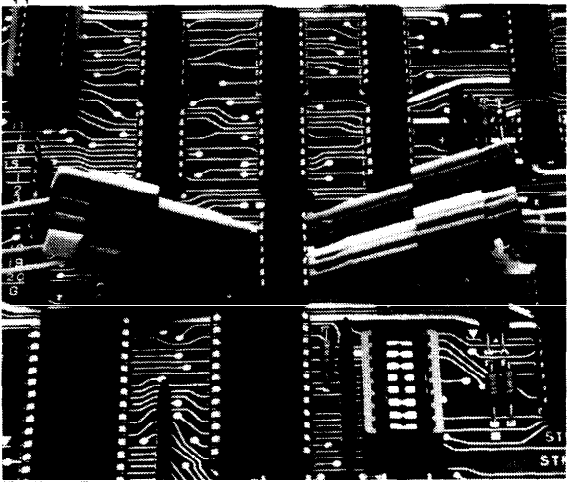

COLOR CHART	
Black	Green
Brown	Blue
Red	Violet
Orange	Grey
Yellow	White

PICO-HOOK: One-Piece, Gold Plated Conductor and Hook per MIL G45204. Made for connections over component leads up to .025"(.635mm) diameter. Durable plastic body and plunger. Stainless steel compression spring provides approximately 8 ounces (227 grams) contact pressure.

LEAD WIRE: 28 AWG 19 x 40 T.C. PVC insulation.
24 AWG 19 x 36 S.C. Teflon insulation to 200°C.


COLOR CHOICES	1. Single Color Unit: Add desired color to Part No. See Color Chart.
	2. Color Assortment (1 each of 10 Colors): Add -S after Part Number.
	3. Multicolor Unit: See Kilo-Color Ordering Information on inside back cover.

For Non-Magnetic Pico-Hook add -NM to part number Example: P713-NM-(Length)

E-Z-PICO-HOOK™ TEST LEADS

PICO-HOOK TO PICO-HOOK JUMPER

PVC	Lead	e n g t h	TEFLON
P704-3	3"	8cm	P304-3
P704-6	6	15cm	P304-6
P704-12	12"	30 cm	P304-12
P704-18	18"	45 cm	P304-18
P704-24	2 4	60 cm	P304-24
P704-36	3 6	90 cm	P340-36

 

PICO HOOK, LEAD WIRE DESCRIPTIONS AND COLOR CHOICES: See Basic PICO HOOK.