




LED FIL T28X115 E14 DIM 8.5W (81W) 1160lm 830 Frosted Opal

Article number: 146788

BAI LED Filament T28x115mm E14 220-240V 8.5W (81W) 1160lm 3000K Dimmable Frosted Opal FLOS LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. The so-called filaments replace the traditional filament, making the lamps many times more energy-efficient and last much longer. This lamp is dimmable (depending on the type of dimmer and the number of lamps to be dimmed on 1 dimmer). This LED can be used in the FLOS IC Lights. Ambient temperature range: -20°C to +40°C.

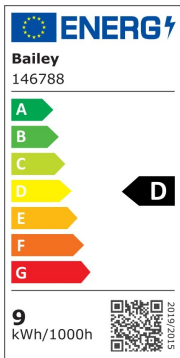

General ETIM properties


ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL T28X115 E14 DIM 8.5W (81W) 1160lm 830 Frosted Opal
Brand	Bailey
Productseries	LED Filament tube
Producttype	T28x115

ETIM specifications

Socket	E14
Luminous flux [lm]	1180 - 1180
Nominal voltage [V]	220 - 240
Lamp power [W]	8.5 - 8.5
Colour temperature [K]	3000 - 3000
Diameter [mm]	28
Length [mm]	115
Dimmable	Yes
Lamp shape	Tube, single-ended
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Opal
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	1180
Power factor	0.7
Lamp efficacy [lm/W]	139
Nominal current [mA]	50 - 50
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	9
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	D
With twilight switch	No
Material of light bulb	Glass

Complementary articles

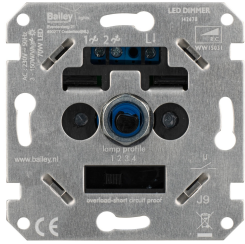

142678
Bailey WW15031 LED Wall Dimmer RC 3-150W



142227
Lampholder Porcelain E14 White