


# DX06LG024N Datasheet

Product Name // DX06LG024N, 6mm Diameter, Solder Lug,  
Green, 24V, Nickel Plated Brass

 [View Product Page](#)

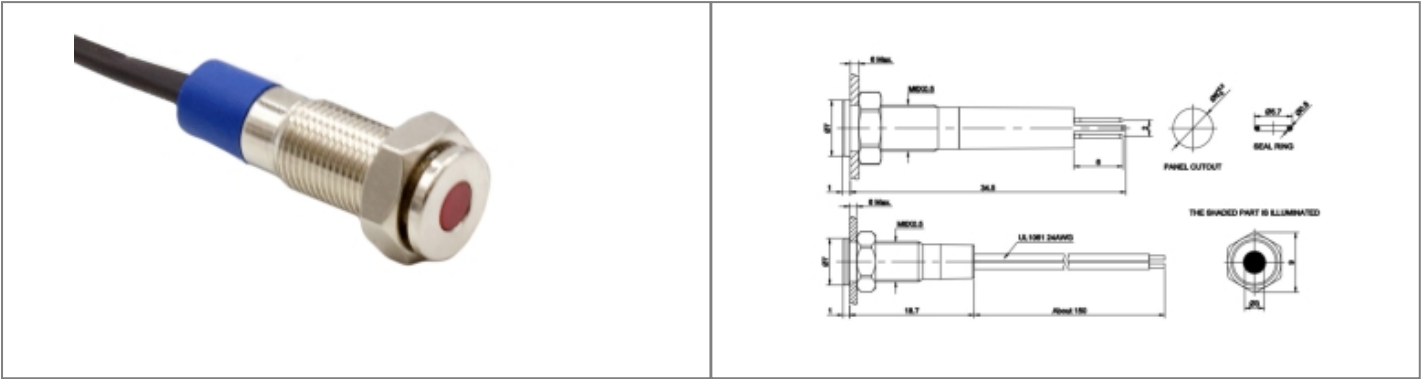

## // Product Description:

- |                                                                                                 |                                                                                                         |
|-------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------|
|  DX Series     |  Green                 |
|  6mm Diameter |  24V                  |
|  solder Lug  |  Nickel Plated Brass |

## // General Information:

|                                  |                                         |
|----------------------------------|-----------------------------------------|
| Product Display Title:           | 6mm Vandal Resistant Indicator DX Range |
| Product Family:                  | Indicators                              |
| Product Series:                  | 6mm Vandal Resistant Indicator DX Range |
| Bezel Finish:                    | Polished                                |
| Body Colour:                     | Nickel                                  |
| Body Material:                   | Brass                                   |
| Body Material Type:              | Metal                                   |
| Diameter:                        | 6mm                                     |
| Dielectric Withstanding Voltage: | 1500V                                   |
| Function:                        | Vandal Resistant Indicator              |
| Illumination Colour:             | Green                                   |
| Illumination Voltage:            | 24V                                     |
| Indicator Profile:               | Flat-round                              |
| Insulation Resistance:           | ≥100MΩ(500VDC)                          |
| Ip Rating:                       | IP67                                    |
| Material Finish:                 | Polished                                |
| Max Operating Temperature:       | 55°C                                    |
| Min Operating Temperature:       | -25°C                                   |
| Max Panel Thickness:             | 6mm                                     |
| Panel Cut Out:                   | 6mm Diameter circle                     |
| Rohs Compliant:                  | Yes                                     |
| Thread Size:                     | M6 X 0.5                                |

### // Product PDF Links

 [6mm & 8mm Vandal Resistant...](#)

### // Product 3D CAD Model Links

 [DX06LG024N3D CAD Model](#)



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)