
7511

Lamps with metal bases for trucks



Areas of application

- Position and parking light
- Indicator, brake, fog and reversing lights
- Number plate and side position lights

Product benefits

- OEM Quality
- Wide product range
- Reliable quality

Product features

- Original spare parts

Technical data


Electrical data

Power input	28 W
Nominal wattage	21.0 W
Nominal voltage	24.0 V
Power input tolerance	±6 %
Test voltage	28.0 V

Photometrical data

Luminous flux	460 lm
Luminous flux tolerance	±15 %

Dimensions & weight

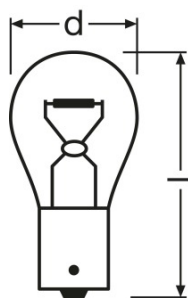

Length	52.5 mm
Diameter	26.5 mm

Lifespan

Lifespan B3	200 h
Lifespan Tc	400 h

Additional product data

Base (standard designation)	BA15s
-----------------------------	-------

Certificates & standards

ECE category	P21W
--------------	------

Country specific categorizations

Order reference	7511 21W 24V BA
-----------------	-----------------

Product datasheet

Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4050300838090	OSRA7511	-	4739921	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300838090	7511	Unpacked 1	47 mm x 21 mm x 23 mm	0.02 dm ³	18.00 g
4050300525228	7511	Folding carton box 10	64 mm x 54 mm x 132 mm	0.46 dm ³	113.00 g
4008321090980	7511	Shipping carton box 50	273 mm x 65 mm x 145 mm	2.57 dm ³	615.00 g
4050300925929	7511	Blister 2	95 mm x 35 mm x 62 mm	0.21 dm ³	23.20 g
4008321140500	7511	Shipping carton box 20	280 mm x 104 mm x 81 mm	2.36 dm ³	286.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.