



Product data sheet

Power tools for trade & industry

Wall Chaser

PRO GNF18V-40



Powerful cordless wall chaser with enhanced tool control and high cutting depth

The most important data

No-load speed	4,700 rpm
Cutting depth, max.	40 mm

Part Number 0 601 6C5 000

Technical data

Technical data

Adjustable groove depth	10 – 40 mm
Cutting width	2 mm – 3.9 cm
No-load speed	4,700 rpm
Disc diameter	150 mm
Weight	4.2 kg
Packaging dimensions (width x length x height)	357 x 442 x 253 mm
Cutting depth, max.	40 mm
Adjustable slot depth	10 – 40 mm

Noise/vibration information

Sanding solid wood

Vibration emission value a_h	3.7 m/s ²
Uncertainty K	1.5 m/s ²

**BOSCH**


Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- Powerful cordless wall chaser delivering up to 1900 W equivalent corded power* with EXPERT 18V 8.0 Ah or higher batteries
- Superior control in all positions thanks to ergonomic handle layout and balanced design
- Precise cutting guidance with baseplate rollers and clear cut-position markings
- Enhanced user protection with efficient dust extraction, brake function, and restart protection

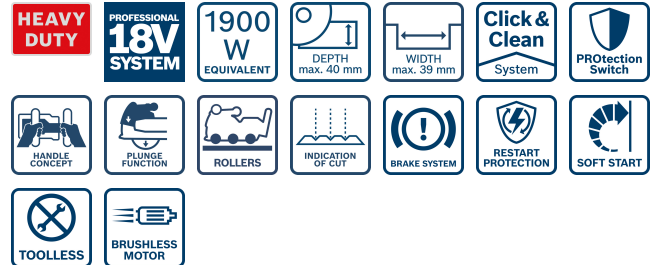

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/gb/en/wac/>

