

# 95 62 190 T

## Wire Rope Cutter with tether attachment point with tether attachment point



- With two crimping dies for end caps on Bowden cable sheaths and end ferrules for traction cables
- Comfortable work thanks to handy, slim design and internal opening spring
- Bolted joint for precise blade guidance, re-adjustable
- High leverage for reduced effort
- Cutting-edge hardness approx. 64 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened
- Pliers with tether attachment point for mounting a fall protection



Cuts all wire ropes without splaying, including those that are extremely strong


<b>Article No.</b>	95 62 190 T
<b>EAN</b>	4003773014539
<b>Head</b>	burnished
<b>Handles</b>	with multi-component grips, with integrated tether attachment point for a tool tether
<b>Cutting capacity copper cable, multiple-stranded (diameter) Ø mm</b>	7,0
<b>Cutting capacities wire rope (diameter) Ø mm</b>	5,0
<b>Cutting capacities medium hard wire (diameter) Ø mm</b>	4,0
<b>Cutting capacities piano wire (diameter) Ø mm</b>	2,5
<b>AWG</b>	7
<b>Length mm</b>	190
<b>Net weight g</b>	345



Crimping of the end ferrule onto the traction cable



Crimping of the end caps on the Bowden cable sheath

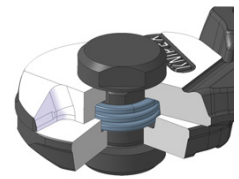

Internal opening spring

technical change and errors excepted