 



pressure regulator LR-1/8-D-7-MICRO

Part number: 526263
Classic

FESTO

With threaded connection plate and pressure gauge
Modern alternatives can be found by entering the first four characters
of the type code in the search field.

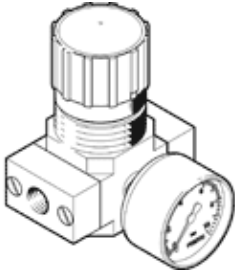

Data sheet

Feature	Value
Size	Micro
Series	D
Actuator lock	Rotary knob with lock
Assembly position	Any
Design structure	directly-controlled diaphragm regulator
Controller function	with secondary exhaust
Pressure gauge	with pressure gauge
Operating pressure	1 ... 10 bar
Pressure regulation range	0.5 ... 7 bar
Max. pressure hysteresis	0.3 bar
Standard nominal flow rate	230 l/min
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	110 g
Mounting type	Optional Line installation with accessories
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminium alloy
Material seals	NBR
Material housing	Wrought Aluminium alloy
Material membrane	NBR