

Wall mounted socket
Part no. 143




- screw terminals
- X-CONTACT®
- products with pilot contact on request

Technical specifications

Ampere	125 A
Poles	5 p
Voltage	400 V
Clock position	6 h
Hertz	50-60 Hz
Connection technology	Screw terminals
Contact	highly heat resistant contact carrier, X-CONTACT
Protection type	IP67
Weight	2102 g

Drawing

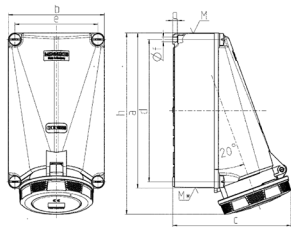

Drawing	Amp.	125
1 MB 162	Poles	4 5
Dim. in mm	a	264 264
	b	163 163
	c	200 200
	d	240 240
	e	140 140
	f	8.1 8.1
	g	8 8
	h	306 306
	M	50 50
	M*	50 50
Max. cable diam. (mm)		38 38
Terminal for cond. cross section (mm²) min.-max.		25 25
		—35 —35