



Einhell

PROFESSIONAL



Cordless Jig Saw

TP-JST 18/135 Li BL - Solo

Item No.: 4321265


Ident No.: 21012

Bar Code: 4006825670486

The Einhell Professional cordless jigsaw TP-JST 18/135 Li BL is part of the combinable Power X-Change family. The device is powered by a brushless motor for more power and longer runtime. After online registration, there is a 10-year warranty on the motor. The special T-Style handle ensures optimal guidance of the saw even overhead. The cordless jigsaw creates cuts up to 135 mm deep in wood and 10 mm in steel as well as oblique cuts up to 45° and is equipped with speed electronics, a cutting line indicator and a tool-free saw blade holder. Delivery with 3x jigsaw blades for wood, but without battery or charger.

Features & Benefits


- Member of the Power X-Change family, 1x 18 V battery required
- Brushless motor – more power and longer running time
- PurePOWER brushless – 10-year motor warranty after registration
- T-style handle for easy tool guidance over head
- Impressively smooth-running for precise cuts
- Switchable pendulum stroke for fast cuts
- Speed electronics for optimal tool control
- Tool-free saw blade attachment
- Dust blow-off function for best view of the working area
- LED light to illuminate the cutting area
- Cutting line indicator for precise cuts
- Locking switch for continuous operation
- Aluminium inner housing and base plate for reduced vibrations
- Plastic shoe cover protects delicate workpieces
- Rip fence for precise, straight cuts
- Incl. chip tear protection for tear-free cuts
- Dust extraction with 90° angle – optimal hose position
- Hexagon key included for angle adjustment
- Incl. 3x jigsaw blades for wood
- Supplied without battery and charger (sold separately)

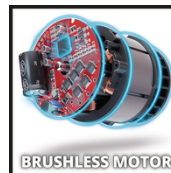

BRUSHLESS MOTOR



T-STYLE

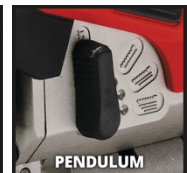

PENDULUM

Technical Data

- No-load speed	0 - 3500 min ⁻¹
- Stroke height	26 mm
- Cutting depth in wood	135 mm
- Cutting depth in plastic	20 mm
- Cutting depth in steel	10 mm
- Max. bevel cuts	45 °
- Toolless saw blade change	yes



PERFECT VIEW



**BATTERY &
CHARGER**

**NOT
INCLUDED**

Logistic Data


- Product weight	1.96 kg
- Gross weight single packaging	2.95 kg
- Dimensions single packaging	206 x 97 x 349 mm
- Pieces per export carton	5 Pieces
- Gross weight export carton	15 kg
- Container quantity (20"/40"/40"HC)	3370 6985 8190



18 V




BRUSHLESS

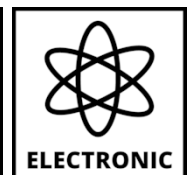

ELECTRONIC

 Available as special accessories



Stich-Sägeblatt Box 10-tlg. T
Stichsägen-Zubehör
Item No.: 49617350
Bar Code: 4009316173503
Einhell Accessory



St-Sägebl.Set 4tg Ho/Met Akku
Stichsägen-Zubehör
Item No.: 49625427
Bar Code: 4009316254271
Einhell Accessory



5,2 Ah Power X-Change Plus
Battery
Item No.: 4511437
Bar Code: 4006825616606
Einhell Accessory



PXC+ 18V 5-8Ah MULTI
Battery
Item No.: 4511600
Bar Code: 4006825665055
Einhell Accessory



PXC+ 18V 4,0Ah
Battery
Item No.: 4511553
Bar Code: 4006825660869
Einhell Accessory



3,0 Ah Power X-Change Plus
Battery
Item No.: 4511501
Bar Code: 4006825644197
Einhell Accessory



2,0 Ah Power X-Change
Battery
Item No.: 4511395
Bar Code: 4006825610369
Einhell Accessory



4,0 Ah Power X-Change
Battery
Item No.: 4511396
Bar Code: 4006825610376
Einhell Accessory



4-6 Ah Multi-Ah Power X-Change
Plus
Battery
Item No.: 4511502
Bar Code: 4006825644210



PXC 18V 2,5Ah
Battery
Item No.: 4511516
Bar Code: 4006825650518
Einhell Accessory



2x 18V 5,2Ah PXC-Twinpack
Battery
Item No.: 4511526
Bar Code: 4006825656695
Einhell Accessory



2x18V 4,0Ah PXC-Twinpack CB
B1
Battery
Item No.: 4511489
Bar Code: 4006825638578



2x2 Power X-Quattrocharger 4A
Charger
Item No.: 4512102
Bar Code: 4006825649536
Einhell Accessory



Power X-Fastcharger 4A
Charger
Item No.: 4512103
Bar Code: 4006825650228
Einhell Accessory



Power X-Twincharger 3A
Charger
Item No.: 4512069
Bar Code: 4006825629729
Einhell Accessory



Power X-Car Charger 3A
Charger
Item No.: 4512113
Bar Code: 4006825655377
Einhell Accessory



Power X-Boostcharger 8A
Charger
Item No.: 4512155
Bar Code: 4006825670554
Einhell Accessory



18V 2,5Ah PXC Starter Kit
PXC-Starter-Kit
Item No.: 4512097
Bar Code: 4006825646962
Einhell Accessory



2x 4,0Ah & Twincharger Kit 1
PXC-Starter-Kit
Item No.: 4512112
Bar Code: 4006825655766
Einhell Accessory



18V 4-6Ah & 6A Boostcharger
PXC-Starter-Kit
Item No.: 4512143
Bar Code: 4006825667653
Einhell Accessory



18V 4,0Ah PXC Starter Kit B1
PXC-Starter-Kit
Item No.: 4512042
Bar Code: 4006825613704
Einhell Accessory

Battery-Running-Times



One Battery for All

1.5 Ah	11
2.0 Ah	14
2.5 Ah	18
3.0 Ah	21
4.0 Ah	29
5.2 Ah	37
6.0 Ah	43
8.0 Ah	57

Test setup:

1) wood - chipboard 19 mm