


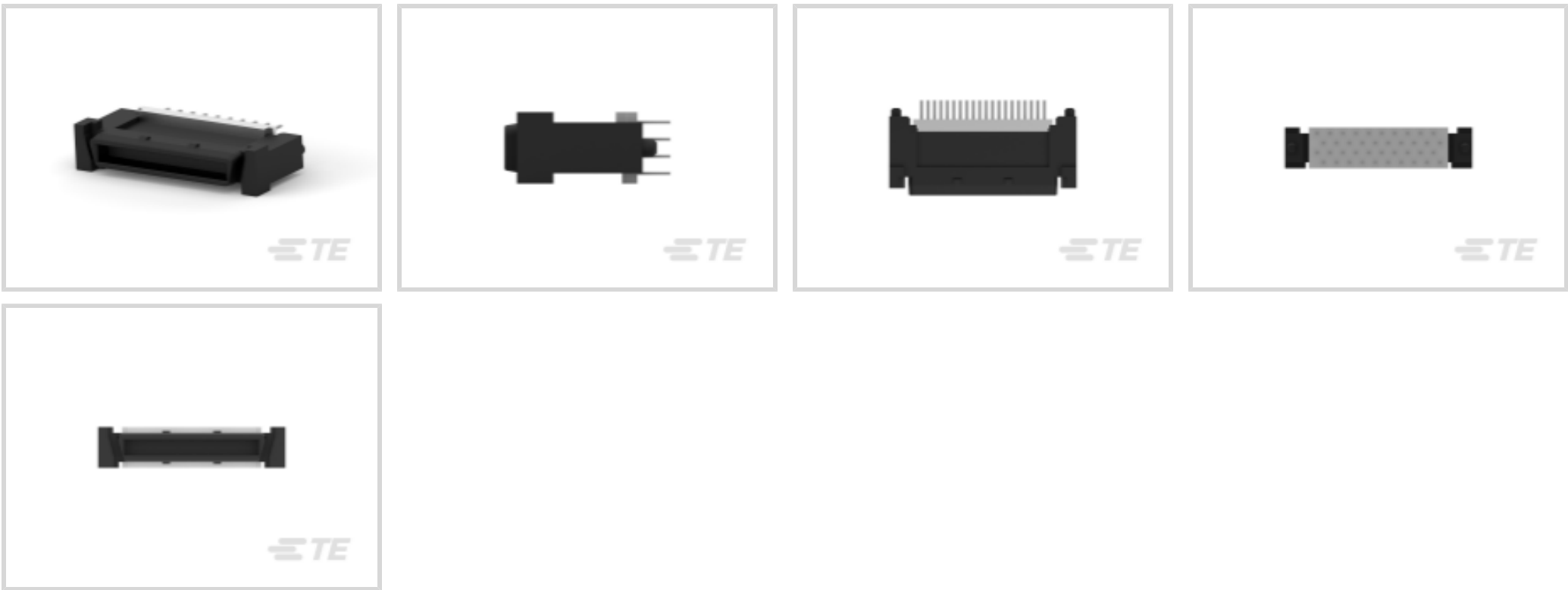

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5176372-2
AMP FH CONN REC V 60P (H=11)



TE Part # 5176376-2
AMP FH CONN REC V 60P (H=16)



TE Part # 5176374-2
AMP FH CONN REC V 60P (H=14)



TE Part # 5176371-2
AMP FH CONN REC V 60P (H=11)



TE Part # 5176381-2
PLUG ASS'Y(H) 60P 1.27FHBB



TE Part # 5176379-2
REC ASS'Y(H) 60P 1.27FHBB



TE Part # 5917629-2
AMP FH REC V 60P H-9 SIF

Customers Also Bought




TE Part #1-1634009-0
MMCX Str PCB Skt 50Ohm Gold Pl



TE Part #5414409-1
BNC PCB RT ANG JACK W/POST



TE Part #CAT-D9934-A66B
DYNAMIC 2000 HDR ASSY

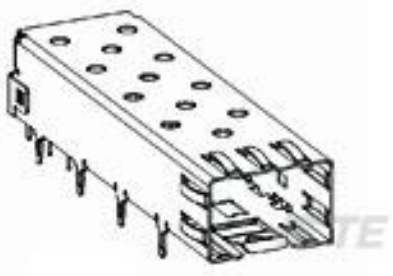

TE Part #2227303-2
CAGE ASSEMBLY, SFP, .071 TAIL



TE Part #1241050-5
2x5P MOD II BREAK AWAY HDR,SMD, BLISTER



TE Part #1-1393586-9
V23535A2200A261=BKMOD421 HEADE



TE Part #3-1768421-7
LBG-U-03194/4/EET0814



TE Part #5917628-2
REC ASS'Y(V) 60P 1.27FHBB

Documents

Product Drawings
REC ASS'Y(V) 60P 1.27FHBB
English

CAD Files
Customer View Model
ENG_CVM_5176378-2_O.3d_igs.zip
English
Customer View Model



[ENG_CVM_5176378-2_O.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_5176378-2_O.2d_dxf.zip](#)

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English

AMP FH CONNECTOR

English

Product Specification

English

Instruction Sheets

AMP FH Board-to-Board Connectors

English

Instruction Sheet (non U.S.)

English