


53801036



Pipe Cleaning Brush f/handle, 170 mm, Medium, Yellow

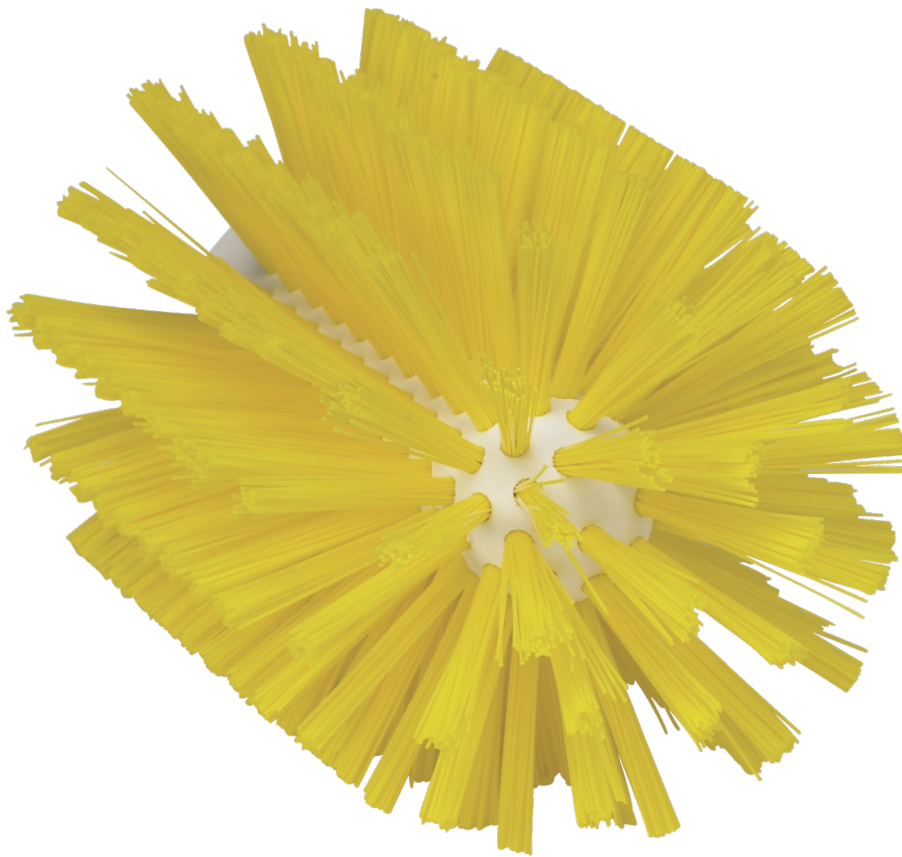

This tube brush has bristles along the sides as well as in the front. It is used in areas where a wider tube cleaning action is required or where the equipment being cleaned, has an end point that cannot be reached with a hand brush. Also used for drain cleaning.

Technical Data

Item Number	53801036
Visible bristle length	37 mm
Material	Polypropylene Polyester Stainless Steel
Suitable for Food Contact (EU 1935/2004), DoC ¹	Yes
Produced according to EU Regulation 2023/2006/EC of Good Manufacturing Practice	Yes
FDA compliant raw material (CFR 21)	Yes
Meets the REACH Regulation (EC) No. 1907/2006	Yes
Use of Phthalates (e.g. Bisphenol A)	No
Is Halal compliant	Yes
Box Quantity	12 Pcs.
Quantity per Pallet (80 x 120 x 200 cm)	576 Pcs
Quantity Per Layer (Pallet)	72 Pcs.
Box Length	410 mm
Box Width	300 mm
Box Height	210 mm
Product Diameter	103 mm
Length	170 mm
Width	100 mm
Height	100 mm
Gross Weight	0,182 kg
Net Weight	0,16 kg
Cubik metre	0,0017 M3
Recommended sterilisation temperature (Autoclave)	121 °C
Max. cleaning temperature (Dishwasher)	93 °C
Max usage temperature (food contact)	80 °C
Max usage temperature (non food contact)	100 °C
Min. usage temperature	-20 °C
Min. pH-value in usage concentration	2 pH
Max. pH-value in Usage Concentration	10,5 pH
Gtin-13 Number	5705025380612
GTIN-14 Number (Box quantity)	15705025380619
Commodity Code	96039099
Country of origin	Denmark

New equipment should be cleaned, disinfected, sterilised and any labels removed, as appropriate to its

intended use, e.g. high risk vs. low risk food production areas, general hospital areas vs. intensive care units, before use.