

Datasheet

RS Pro Midget Groove Filament Indicator Lamp, Clear, 28 V, 40 mA, 10000h

RS Stock No: **360-7660**



Product Details

RS Pro midget groove filament indicator lamp works with currents up to 40 mA and voltages up to 28 V. This clear light delivers 3.8 lumens of bright output with a lifetime of 10000 hours.

Features and Benefits


- Clear light
- 3.8 lumens output
- 10000 hours lifetime



Specifications:

Current Rating	40 mA
Diameter	5.84 mm
Lamp Base	Midget Groove
Lamp Size	T1 3/4
Length	15.87 mm
Lens Colour	Clear
Life Hours	10000 h
Luminosity	3.8 lm
Voltage Rating	28 V

DRAWING - I

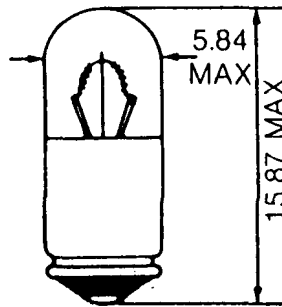

Unit : mm

1. Structure	Bulb Diameter	5.84mm Max.
	Length	15.87mm Max.
	Base Type	Midget Groove
2. Design Characteristics	Voltage	28V
	Amperage	40mA ± 10%
	Filament Type	C-2F
		Vacuum type
	MSCP	0.3 CP ± 20%
Life Hours	10000 Hrs	