




**147-30**

**30 mm Open End Insert for 14 mm  
x 18 mm Rectangular Connector  
Wrench**



## PRODUCT DETAILS

- Insert is fixed to the torque wrench by a spring-loaded retractable pin
- Range covers from 9x12 to 27x36 receivers, from 7 to 90 mm openings, from 9 to 3,000 N·m
- Sizes with \* in torque length require a target torque setting calculation
- Suitable for 7465, 74W9, 74W14, 74P9, 74P14, IZO-D, TAW9, TAW14, TAW24, TAWM9, TAWM14, TAWM24 wrenches

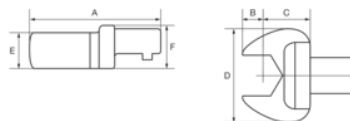

**Follow the Fish!**



PRODUCT ATTRIBUTES

| Product |  |  |  | A     | B     | C      | D     | E     | F     |  |
|---------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-------|-------|--------|-------|-------|-------|-------------------------------------------------------------------------------------|
| 147-30  | 30 mm                                                                             | 14x18 mm                                                                          | 360 N·m                                                                           | 75 mm | 17 mm | 35* mm | 65 mm | 14 mm | 20 mm | 270 g                                                                               |

