

## Features

- VDE 0682 Part 201, ISO 8764
- For live working up to 1000V AC or 1500V DC
- Chrome Vanadium Molybdenum steel blade (phosphate finish)
- TPE/PP Softgrip handle
- Individually tested as per DIN EN 60900: 2004 norm
- Tested to 10,000V AC
- Tip Size: PZ0

## RS PRO Series Insulated Pozidriv Screwdrivers, PZ0 Tip (VDE)

RS Stock No.: 197-3795



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

RS Pro Insulated Pozidriv screwdrivers offer maximum comfort and grip, suitable for safe working on live equipment at up to 1000V AC or 1500V DC.

## General Specifications

Blade Finish	Phosphate finish
Blade Material	Chrome Vanadium Molybdenum
ESD Safe	No
Handle Material	TPE/PP Soft grip handle
Height Safe	No
Non Sparking	No
Number of Pieces	1
Screwdriver Type	Pozidriv


## Approvals

Standards Met	VDE/1000V Approved
---------------	--------------------

## Similar Products

Stock No.	Brand	Product Name	Attribute 1	Attribute 2	Attribute 3	Attribute43
197-3795	RS PRO	Pozidriv Insulated Screwdriver PZ0	Pozidriv	PZ0	Blade length 60mm	Overall length 150mm
125-3086	RS PRO	Pozidriv Insulated Screwdriver PZ0	Pozidriv	PZ1	Blade length 60mm	Overall length 150mm
125-3087	RS PRO	Pozidriv Insulated Screwdriver PZ0	Pozidriv	PZ2	Blade length 60mm	Overall length 150mm
197-3796	RS PRO	Pozidriv Insulated Screwdriver PZ0	Pozidriv	PZ3	Blade length 60mm	Overall length 150mm

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories

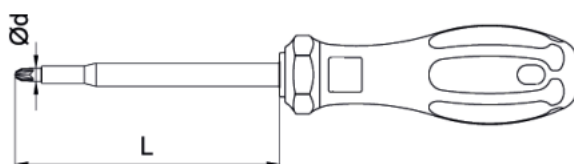

1000 V  
EN 60900