

## Contact insert module - HC-1/2M-UT-M-6-PE - 1424439

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Contact insert module, Pin, leading, Screw connection, 0.5 mm<sup>2</sup> ... 6 mm<sup>2</sup>, application: PE transmission, for housing size HC-EVO-M1



COMPLIANT

### Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4055626372587
Weight per Piece (excluding packing)	17.200 g
Custom tariff number	85366990
Country of origin	China

### Technical data

#### Dimensions

Height	43.7 mm
Width	30.9 mm
Length	7.7 mm

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

#### Mechanical characteristics

Conductor cross section	0.5 mm <sup>2</sup> ... 6 mm <sup>2</sup>
Connection cross section AWG	20 ... 10
Contact diameter	4 mm
Insertion/withdrawal cycles	≥ 500

#### General

Note	For HEAVYCON housing type HC-EVO-M1
	Connectors may be operated only when there is no load/voltage.

# Contact insert module - HC-1/2M-UT-M-6-PE - 1424439

## Technical data

### General

Series	HC-EVO-M1
Color	silver
Connection method	Screw connection
Contact type	turned
Flammability rating according to UL 94	V0

### Material data

Contact carrier material	Die-cast zinc alloy
--------------------------	---------------------

### Standards and Regulations


Flammability rating according to UL 94	V0
--	----

### Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings

Dimensional drawing

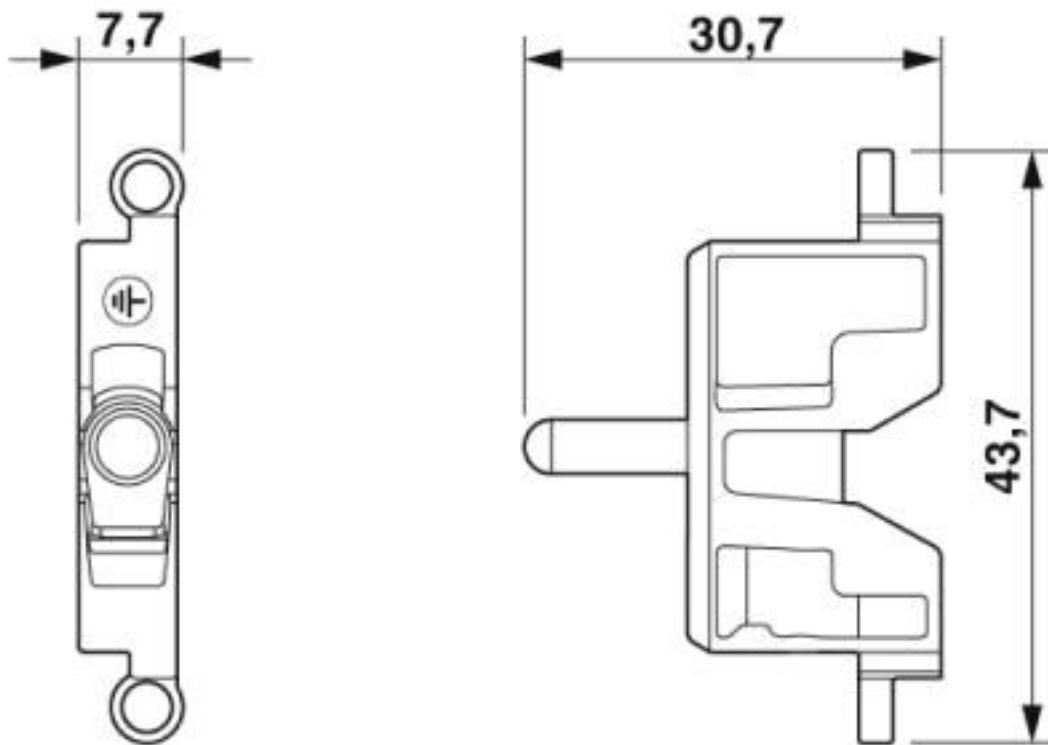

# Contact insert module - HC-1/2M-UT-M-6-PE - 1424439

## Classifications

### eCl@ss

eCl@ss 10.0.1	27440217
eCl@ss 9.0	27440217

### ETIM

ETIM 6.0	EC000438
ETIM 7.0	EC000438

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

EAC		RU C- DE.BL08.B.00511
-----	--	--------------------------

## Accessories

### Accessories

#### Housing with locking latch

Housing - HC-EVO-M1-HHFS-PLBK - 1424436



Sleeve housing, plastic, with bayonet flange for EVO-D screw connection, M1, for single locking latch, for modular contact inserts with single module width, without EVO screw connection

### Screwdriver tools

## Contact insert module - HC-1/2M-UT-M-6-PE - 1424439

### Accessories

Philips screwdriver - SF-PH 1-80 - 1212559



Screwdriver, PH crosshead (lasered), uninsulated, size: PH 1 x 80, 2-component grip, with non-slip grip

---

Screwdriver - SF-SL 0,6X3,5-100 - 1212549



Screwdriver, bladed (lasered), size: 0.6 x 3.5 x 100 mm, 2-component grip, with non-slip grip

---

### Additional products

Contact insert module - HC-1/2M-UT-F-6-PE - 1424438



Contact insert module, Socket, Screw connection, 0.5 mm<sup>2</sup> ... 6 mm<sup>2</sup>, application: PE transmission, for housing size HC-EVO-M1

---

---