

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 2103191-4
CAP SUBASSY, KEY D, HVA280-2PHI



TE Part # 2395340-2
Daimler HVA 280 2PHI Pigtail



TE Part # 2103191-5
CAP SUBASSY, KEY E, HVA280-2PHI



TE Part # 2103191-6
CAP SUBASSY, KEY F, HVA280-2PHI



TE Part # 2103191-1
CAP SUBASSY, KEY A, HVA280-2PHI



TE Part # 2103191-2
CAP SUBASSY, KEY B, HVA280-2PHI


Customers Also Bought



TE Part #2112286-1
COVER,90,FOR REC. CARRIER 25/36P



TE Part #2040594-2
SEAL CAP HSG 3P, AMPSEAL16 SEA

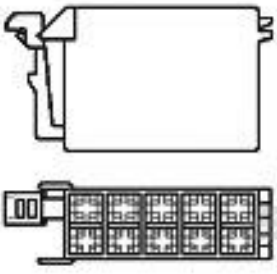

TE Part #962190-1
10P JUNIOR-TIMER GH



TE Part #YHVA280-2PHI-4MM-A
HVA280-2PHI XE,4SQMM,KEY A



TE Part #2029060-1
MINI UMNL LATCH LOCK



TE Part #HPP816E056
TRICAN 24V HTD2800P1B11C6STD



TE Part #1544358-1
CLIP 2,8 DRAP. 0,2



TE Part #1587828-3
INNER FERRULE, SIZE C, HVA280-2PI



TE Part #2103191-1
CAP SUBASSY, KEY A, HVA280-2PHI



TE Part #1587723-3
INNER FERRULE, SIZE C, HVA280

Documents



Product Drawings

CABLE SEAL RETAINER, SIZE C

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1587940-3_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1587940-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1587940-3_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.