


Dial indicators in a satin-chromed body.

Features

- Double dial indicator for measuring mm stroke
- MW400-01 to MW400-06 have jewel bearings
- Satin-chromed body
- Tungsten carbide contact point
- Adjustable bezel with stop screw
- Shock proof
- Standard: DIN 878

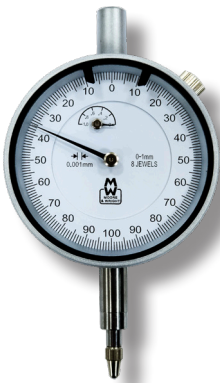

MW400-01



MW400-02



MW400-03



MW400-04



MW400-05



MW400-06



MW400-06B



MW400-08



MW400-09

Specification					
Code No	Range (mm)	Resolution (mm)	Accuracy (mm)	Dial Diameter (mm)	Description
MW400-01	0-1.0	0.001	±0.004	58	Flat back
MW400-02	0-1.0	0.001	±0.004	58	Lug back
MW400-03	0-3.0	0.01	±0.012	42	Lug back and flat back
MW400-04	0-5.0	0.01	±0.014	42	Lug back
MW400-05	0-10.0	0.01	±0.016	58	Flat back
MW400-06	0-10.0	0.01	±0.016	58	Lug back
MW400-06B	0-10.0	0.01	±0.02	54	Waterproof
MW400-08	0-30.0	0.01	±0.035	58	Lug back
MW400-09	0-50.0	0.01	±0.04	58	Lug back



Lug Back



Flat Back