


Product data sheet

Specifications

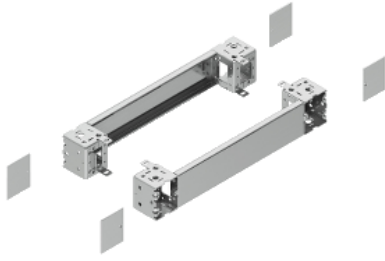

Spacial - plain front panel plinth W600 H100 stainless steel 304L

NSYSPFX6100

Main

Range	Spacial
Accessory / separate part category	Enclosure accessory
Product or component type	Plinth front
Anwendung	Multi-purpose
Device composition	fixing elements 4 corner cover 1 front panel 1 rear panel 4 corner
Range compatibility	Spacial SF Spacial SM Spacial SD Spacial S3D Spacial CRN Spacial SFHD Spacial S3HD Spacial SMX Spacial SFX Spacial SDX Spacial CRNG

Complementary

Fixing mode	By fixing element - on structure location
Surface finish	Untreated
Height	100 mm
Width	600 mm nominal:
Net weight	4.33 kg

Environment

IP degree of protection	IP30 (complete plinth)
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	4.978 kg
Package 1 Height	12.0 cm

Package 1 width	19.0 cm
Package 1 Length	60.5 cm
Unit Type of Package 2	PAM
Number of Units in Package 2	54
Package 2 Weight	282.0 kg
Package 2 Height	100.0 cm
Package 2 width	100.0 cm
Package 2 Length	120.0 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile