

SIVACON, base, EMC, IP40, T: 500 mm, W: 900 mm, zinc-plated



| Model                             |             |
|-----------------------------------|-------------|
| product brand name                | SIVACON     |
| design of the product             | EMC         |
| design of the surface             | zinc plated |
| design of the product EMC version | Yes         |
| material                          | steel       |
| protection class IP               | IP40        |
| product component                 |             |
| • ventilation                     | No          |

| Mechanical Design |         |
|-------------------|---------|
| width             | 900 mm  |
| depth             | 500 mm  |
| net weight        | 5 000 g |

| Approvals Certificates   |                   |       |
|--------------------------|-------------------|-------|
| General Product Approval | Test Certificates | other |



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

|       |             |
|-------|-------------|
| other | Environment |
|-------|-------------|

[Miscellaneous](#)



[Environmental Confirmations](#)

### Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1095-2UB42-0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1095-2UB42-0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=8MF1095-2UB42-0](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1095-2UB42-0)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

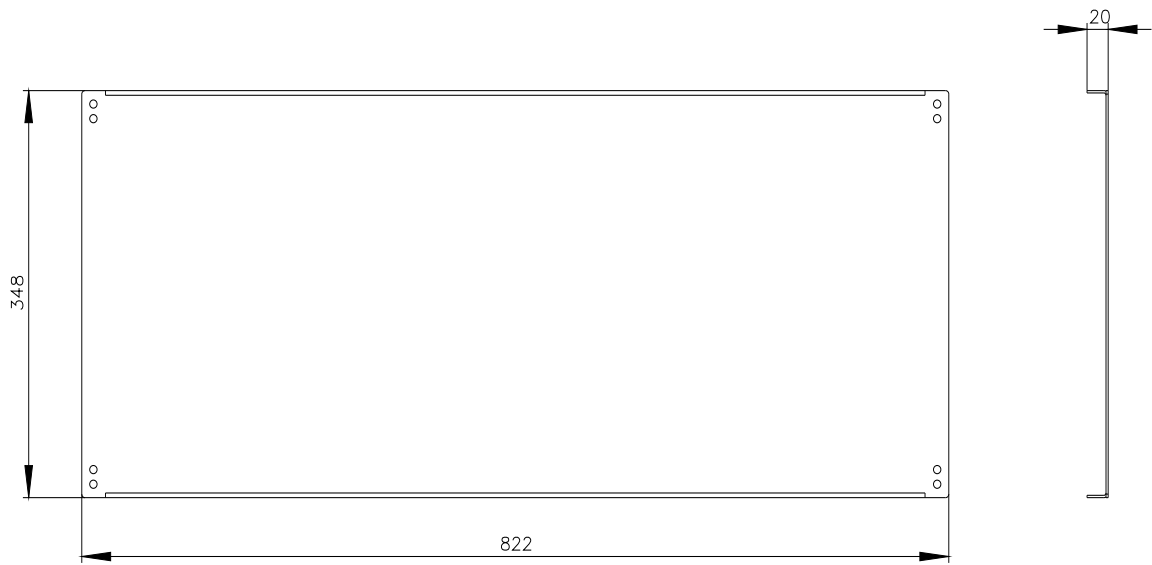

---

last modified:

6/3/2024 

