


Deep groove ball bearings, double row



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
35	72	23	35,1	28,5	1,2	15000	8000	0,40	4207 ATN9

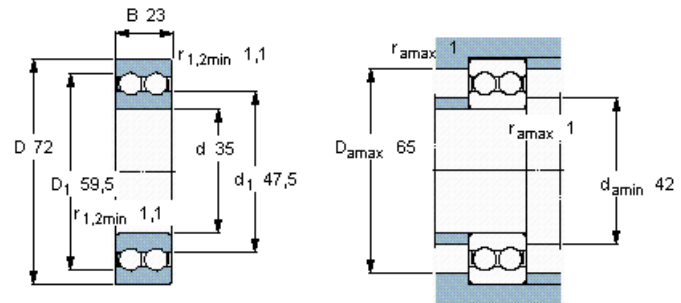

Calculation factors

k_f 0,05
 f_0 14