


blanking plug QSC-10H-50

Part number: 130702

FESTO

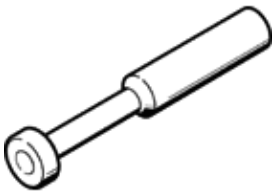

Data sheet

Feature	Value
Size	Standard
Assembly position	Any
Container size	50
Operating pressure complete temperature range	-0.95 ... 6 bar
Temperature dependent operating pressure	-0.95 ... 14 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 80 °C
Product weight	2 g
Pneumatic connection, port 1	Push-in sleeve QS-10
Materials note	Conforms to RoHS
Material housing	PBT