

Features

- HDMI Male
- DVI-D Male
- Length: 2.5m
- Black

RS PRO 2.5m HDMI To DVI D Cable

RS Stock No.: 0839444



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This HDMI to DVI cable is has gold flashed connectors. The HDMI connector uses 19 pins connected to the DVI-D pins on the DVI connector making it DVI-D single link.

Please note: While the connector has the appearance of dual link the dual link pins are not connected.

General Specifications


Connector 1	HDMI
Connector 1 Gender	Male
Connector 2	DVI-D
Connector 2 Gender	Male
Cable Length	2.5m
Cable Colour	Black

Approvals

Standards Met	CE UKCA REACH ROHS
---------------	--------------------

Similar Products

Stock No.	Brand	Product Name
0839445	RS PRO	35cm HDMI M to 2x F Splitter Cable
0839449	RS PRO	1m HDMI to HDMI Mini (C) Cable
0839446	RS PRO	1.5m Flat HDMI High Speed with Ethernet Cable
0839447	RS PRO	2m HDMI Mini (C) Cable
0839444	RS PRO	2.5m HDMI To DVI D Cable

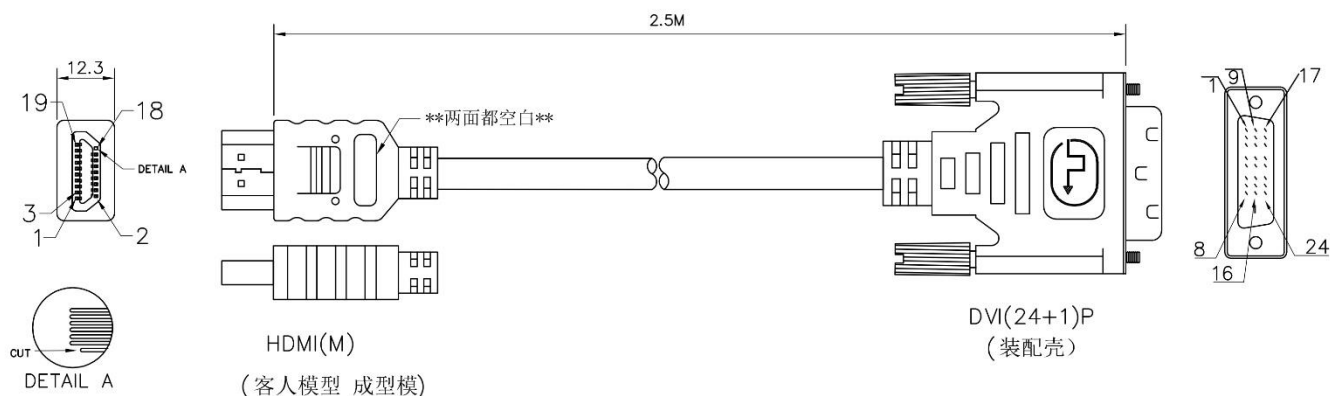

NOTE:

CABLE: 30AWG,UL20276,AL+B-FOIL,[(#30*1P+D+FAM)*4PCS+#30*1P+#30*3C]+AM+B,
BLACK COLOR,OD=6.0±0.2mm,PVC JACKET.(double shielded)

CONNECTORS: HDMI(M)*1PCS(BLACK INSULATOR),DVI(24+1)P*1PCS(BLACK INSULATOR)(全为镀金光)

MOLD: MOLDING TYPE.

SCREW: #4*52 IE32*2PCS. (黑色镀金螺丝)

CONTACTS:

CONNECTIONS																		
HDMI(M)	1	3	2	4	6	5	7	9	8	10	12	11	17	18	15	16	19	64
DVI(24+1)P	2	1	3	10	9	11	18	17	19	23	24	22	15	14	6	7	16	64
	對絞		地	對絞		地	對絞		地	對絞		地	30AWG		30AWG			SHELL

Test machine test condition.

A.100% OPEN,SHORT&INTERMITANCE TEST.

B.CONDUCTOR RESISTANCE: 3ohms MAX:

C.INSULATION RESISTANCE: 5M Min/,10ms:

ALL MUST BE MEET ON ROHS COMPLIANT.