


C9T, Film, Metallized Polypropylene, AC Filter, 31.1 uF, -5/+15%, 415 VAC

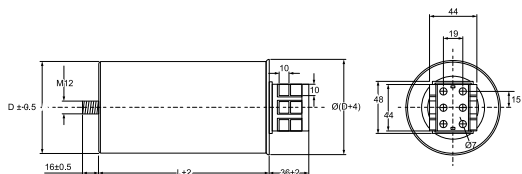

General Information	
Supplier:	KEMET
Series:	C9T
Dielectric:	Metallized Polypropylene
Style:	Can
Features:	Three Phase PFC
RoHS:	Yes
Lead:	Quick Connect
Qualifications:	VDE
Miscellaneous:	Q = 5 kvar. Operating Freq. = 50 Hz

Dimensions	
D	75mm +/-0.5mm
L	160mm +/-2mm

Specifications	
Capacitance:	31.1 uF
Capacitance Tolerance:	-5/+15%
Voltage AC:	415 VAC
Temperature Range:	-25/+55C
Rated Temperature:	55°C
Max dV/dt:	30 V/us
Ripple Current:	9 Amps

Packaging Specifications	
Mounting:	Bolt - M12x16
Packaging:	Bulk, Bag
Packaging Quantity:	12