


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

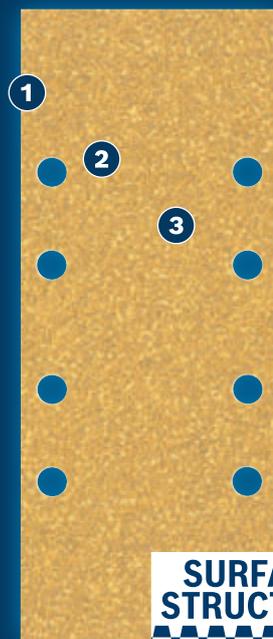

SURFACE
STRUCTURE

UP TO
2x*



* vs. Bosch C420




Video



BOSCH

EXPERT C470 SANDING DISCS

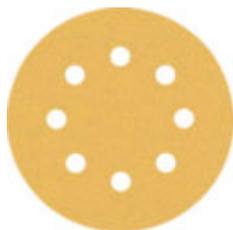

- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop

PRODUCT PROPERTIES			ORDERING INFORMATION				Part number
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	
115	40	8 holes	C1a	5	5	541 327	2 608 900 794
115	60	8 holes	C1a	5	5	541 334	2 608 900 795
115	80	8 holes	C1a	5	5	541 341	2 608 900 796
115	120	8 holes	C1a	5	5	541 358	2 608 900 797
115	180	8 holes	C1a	5	5	541 365	2 608 900 798
115	240	8 holes	C1a	5	5	541 372	2 608 900 799
115	320	8 holes	C1a	5	5	541 389	2 608 900 800
115	400	8 holes	C1a	5	5	541 396	2 608 900 801
125	40	8 holes	C1a	5	5	541 419	2 608 900 803
125	60	8 holes	C1a	5	5	541 426	2 608 900 804
125	80	8 holes	C1a	5	5	541 433	2 608 900 805
125	100	8 holes	C1a	5	5	541 440	2 608 900 806
125	120	8 holes	C1a	5	5	541 457	2 608 900 807
125	180	8 holes	C1a	5	5	541 464	2 608 900 808
125	240	8 holes	C1a	5	5	541 471	2 608 900 809
125	320	8 holes	C1a	5	5	541 488	2 608 900 810
125	400	8 holes	C1a	5	5	541 495	2 608 900 811
125	40	8 holes	C0a	50	1	542 461	2 608 900 908
125	60	8 holes	C0a	50	1	542 478	2 608 900 909
125	80	8 holes	C0a	50	1	542 485	2 608 900 910
125	100	8 holes	C0a	50	1	542 492	2 608 900 911
125	120	8 holes	C0a	50	1	542 508	2 608 900 912
125	150	8 holes	C0a	50	1	544 588	2 608 901 120
125	180	8 holes	C0a	50	1	542 515	2 608 900 913
125	220	8 holes	C0a	50	1	544 595	2 608 901 121
125	240	8 holes	C0a	50	1	542 522	2 608 900 914
125	320	8 holes	C0a	50	1	542 539	2 608 900 915
125	400	8 holes	C0a	50	1	542 546	2 608 900 916



BOSCH