




Part Number : [797581005](#)

Product Description : Pre-Crimped Lead Pico-Lock Female-to-Pico-Lock Female, Gold (Au) Plating, 150.00mm Length, 30 AWG, Black

Series Number : 79758

Status : Active

Product Category : Power and Signal Cable Assemblies

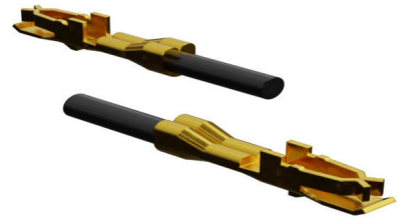

Documents & Resources

Drawings

[797581005_sd.pdf](#)


[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Power and Signal Cable Assemblies
Series	79758
Description	Pre-Crimped Lead Pico-Lock Female-to-Pico-Lock Female, Gold (Au) Plating, 150.00mm Length, 30 AWG, Black
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	Pico-Lock Crimp Terminals
Keyword	Pre-Crimped Leads
Product Name	Pico-Lock
UPC	889056818551

Physical

Cable Length	150.00mm
Circuits (Loaded)	1
Circuits (maximum)	1
Color - Resin	Black
Gender	Female-Female
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	0.656/g
Packaging Type	Bag
Single Ended	No

Termination Interface Style	Crimp or Compression
Wire/Cable Type	UL 1061
Wire Size (AWG)	30

Mates With / Use With

Use with Part(s)

Description	Part Number
1.50mm Pitch, Pico-Lock Single Row Receptacle Housings	<u>504051</u>