

39.3,2H | 39 - METRIC SHORT-REACH COMBINATION WRENCHES




Norm :


NF ISO 691, NF ISO 7738, NF ISO 3318, NF ISO 1711-1, E74-306, ISO 691, ISO 7738, ISO 3318, ISO 1711-1, DIN ISO 691, DIN 1711-1, ASME B107.100

Description :

- Short combination wrenches: the short handle and compact head allow for high handiness. Ideal for confined access.
- OGV® profile with 12-point ring for powerful tightening while protecting the nut.
- H suffix = 6-point ring.
- Ring head angled at 15°.
- Open end head angled at 15°.
- Metric sizes: 3.2 to 17 mm.
- Presentation: satin chrome finish.

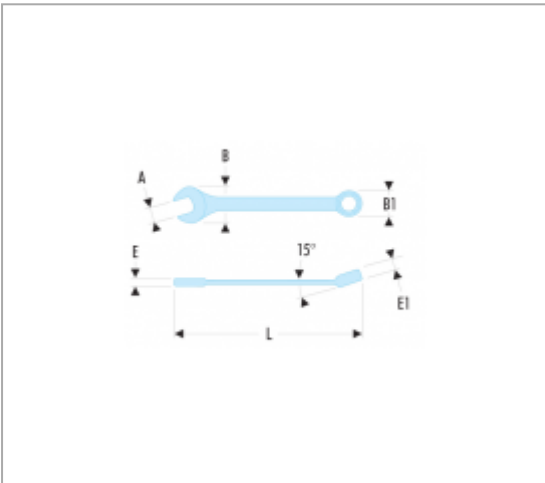

Informations :

	39.3,2H
A [mm]	3,2
B x B1 [mm]	10,0 x 7,0
E [mm]	3,1
E1 [mm]	3,1
L [mm]	77
Hex Size - 12-point [mm]	6
[kg]	0.010