

## RJ45 male insert - VS-08-ST-H21-RJ45 - 1652729


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



RJ45 male insert, CAT6, 8-pos., shielded, IDC displacement connection, for litz wire AWG 25 ... 24 and solid wires AWG 24, with strain relief



### Key commercial data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 017918 952853
Weight per Piece (excluding packing)	4.08 g
Custom tariff number	85366990
Country of origin	Taiwan

### Technical data

#### Mechanical characteristics

Number of positions	8
Insertion/withdrawal cycles	≥ 750
Connection method	IDC connection technology
Conductor cross section	0.16 mm <sup>2</sup> ... 0.22 mm <sup>2</sup> (stranded)
	0.2 mm <sup>2</sup> (solid)
Connection cross section AWG	24 ... 25 (stranded)
	24 (solid)
Cable exit	Straight
Color	red

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 60 °C
---------------------------------	------------------

#### Material data

Inflammability class according to UL 94	V2
Contact carrier material	PC
Contact material	Phosphor bronze

## RJ45 male insert - VS-08-ST-H21-RJ45 - 1652729

### Technical data

#### Material data

Contact surface material	Gold
--------------------------	------

#### Electrical characteristics

Number of positions	8
Transmission characteristics (category)	CAT6
Rated current	1 A
Pollution degree	2

### Classifications

#### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260705
eCl@ss 7.0	27440309
eCl@ss 8.0	27440309

#### ETIM

ETIM 2.0	EC000438
ETIM 3.0	EC000438
ETIM 4.0	EC000438
ETIM 5.0	EC000438

#### UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

### Accessories

#### Accessories

##### Bend protection sleeve

RJ45 bending protection sleeve - VS-08-KS-H/GY - 1654743



RJ45 bend protection sleeve, for pin inserts VS-08-ST-H11-RJ45 and VS-08-ST-H21-RJ45, for cable cross section up to 7 mm, color: gray

## RJ45 male insert - VS-08-ST-H21-RJ45 - 1652729

### Accessories

---

RJ45 bending protection sleeve - VS-08-KS-H/GN - 1654756



RJ45 bend protection sleeve, for pin inserts VS-08-ST-H11-RJ45 and VS-08-ST-H21-RJ45, for cable cross section up to 7 mm, color: green

### Crimping tool

---

Crimping pliers - VS-CT-RJ45-H - 1653265



Crimp tool, pliers with die, for RJ45 pin inserts VS-08-ST-H...-RJ45 and VS-08-RJ45-10G/C

### Sleeve housings

---

RJ45 sleeve housings - VS-08-T-H-RJ45/IP67 - 1652732



RJ45 sleeve housing, IP67, for pin insert VS-08-ST-H11-RJ45 and VS-08-ST-H21-RJ45, with push-pull interlocking for panel mounting frames, for cable cross section 5.0 mm ... 8.5 mm, color: gray

RJ45 sleeve housings - VS-08-T-H-RJ45/IP67-BK - 1658671




RJ45 sleeve housing, IP67, for pin insert VS-08-ST-H11-RJ45 and VS-08-ST-H21-RJ45, with push-pull interlocking for panel mounting frames, for cable cross section 5.0 mm ... 8.5 mm, color: black

### Drawings

## RJ45 male insert - VS-08-ST-H21-RJ45 - 1652729

Dimensioned drawing

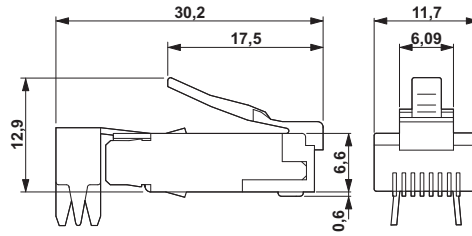

RJ45 male insert