


## Features

- **Highly Versatile Compatibility** – Designed to fit a wide range of single-pole and internal-trip multi-pole breakers, making it a go-to solution for varied panels.
- **Large Breaker Fitment** – Accommodates breaker switches up to 2¼" wide and 7⁄8" thick, ideal for industrial and commercial settings.
- **Durable Construction** – Made from rugged polypropylene and impact-modified nylon for high strength and resistance to damage.
- **Thumbscrew Clamp Mechanism** – Secures firmly to the switch tongue using a **thumbscrew**, then locks with a **flexible flap** to prevent tampering.
- **Shackle Compatibility** – Accepts padlocks with **shackles up to 7 mm**, supporting standard safety padlocks.
- **Flexible, Insulated Design** – Non-conductive flap cover enhances electrical safety, making it ideal for use with **energized electrical equipment**.

## RS PRO Clamp On Circuit Breaker Lockout - Large (Fits on Breaker Switches Up To 2¼" Wide And 7⁄8" Thick)

RS Stock No.: 0710488

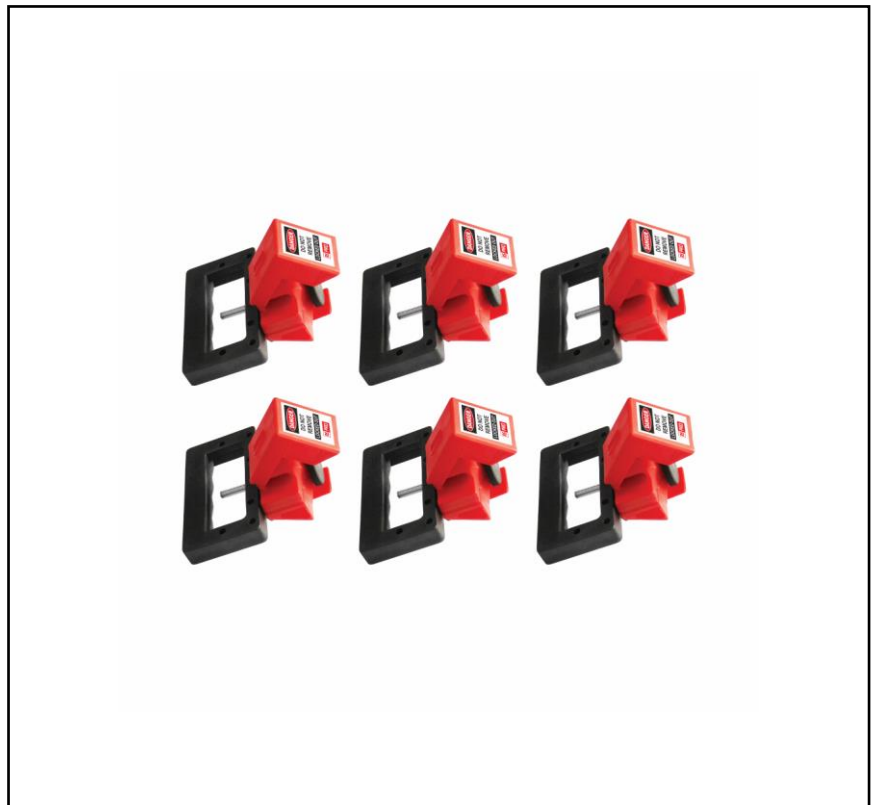

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- **Universal Fit:** Compatible with a wide range of single-pole and internal-trip multi-pole circuit breakers for broad usability across different panels.
- **Industrial-Grade Capacity:** Designed to fit breaker switches up to 2½" (57mm) wide and ⅞" (22mm) thick, suitable for heavy-duty and commercial environments.
- **Rugged Construction:** Built from tough polypropylene and impact-modified nylon for enhanced durability and long-term performance.
- **Secure Locking System:** Features a thumbscrew clamp mechanism and a flexible flap cover that locks in place to prevent unauthorized access.
- **Padlock Friendly:** Supports padlocks with shackles up to 7 mm, allowing integration with standard lockout padlocks.
- **Enhanced Electrical Safety:** Non-conductive, insulated flap ensures safety in electrical lockout applications.

## General Specifications

Type	Circuit Breaker Lockout
Material	Polypropylene, impact modified nylon and SS
Colour	Red & Black
Padlock holes	01
Package	LD

## Mechanical Specifications

A	35mm
B	95mm
C	23.5mm
D	70mm
E	50mm
F	90mm
G	26mm
H	24.5mm
I	4mm
J	55.5mm
K	7mm
Weight	576 Grams

## Operation Environment Specifications

Withstand temperature	-20°C to 80°C
-----------------------	---------------

