




**LED HID FIL T38 E27 26W 4850lm 740 Clear IP20 AC 220V-260V**

Article number: 146456

BAI LED HID Filament Tube E27 26W (70W) 4850lm 4000K CRI70 Clear AC 220V-260V 330° 38X210mm IP20 Alt. NAV-T SON-T LED-Lamp

The LED HID tubular filament lamps are lamps with a high power and a high light output. These LED lamps can serve as a replacement for traditional gas discharge lamps (such as NAV-T and SON-T) under most circumstances. They are similar in shape and look. They light all around and approximately have the same light appearance. But are a lot more durable in use. Traditionally used in luminaires that illuminate paths and areas. The fixture must be suitable for outdoor use and must not become too hot (up to 40°C max.).

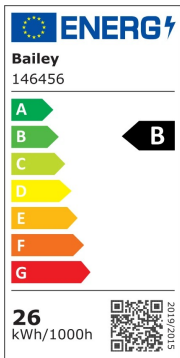

**General ETIM properties**

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED HID FIL T38 E27 26W 4850lm 740 Clear IP20 AC 220V-260V
Brand	Bailey
Productseries	LED HID Filament
Producttype	T38

## ETIM specifications

Socket	E27
Luminous flux [lm]	4850 - 4850
Nominal voltage [V]	220 - 260
Lamp power [W]	26 - 26
Colour temperature [K]	4000 - 4000
Diameter [mm]	38
Length [mm]	210
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	330 - 330
Colour	White
Type of glass/cover	Clear
Lamp designation	T38
Colour rendering index CRI	70-79
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	4850
Power factor	0.9
Lamp efficacy [lm/W]	186
Nominal current [mA]	120 - 120
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Housing colour	Colourless
Average nominal lifetime [h]	25000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	10000
Weighted energy consumption in 1000 hours [kWh]	26
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	B
With twilight switch	No
Material of light bulb	Glass

### Alternative articles



147129  
TForce LED Road E27 26W  
(70W) 4500lm 740



143678  
LED Corn Compact E27 36W  
5400lm 4000K 100V-260V

### Complementary articles



140440  
Surge Protection Device (SPD)  
10KV 110-277V IP65