


95 16 165 Cable Shears



- for cutting copper and aluminium single conductors as well as multiple stranded cables
- not suitable for steel wire and hard drawn copper conductors
- precision ground, hardened blades
- clean and smooth cut without crushing and deformation
- easy cutting with one-hand operation
- guard prevents operators' fingers being pinched
- adjustable bolted joint, self-retaining screw
- High-grade special tool steel, forged, oil-hardened

Article No.	95 16 165
EAN	4003773039648
Tool	chrome plated
Handles	insulated with multi-component grips, VDE-tested
Style	1
Insulation standard	IEC 60900 DIN EN 60900
Cutting capacity copper cable, multiple-stranded (diameter) Ø mm	15
Cutting capacity copper cable, multiple-stranded mm²	50
AWG	1/0
Length mm	165
Net weight g	262

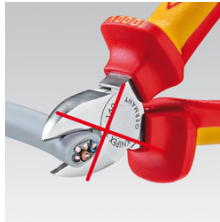

Cut performed with a Diagonal Cutter: high effort required, inaccurate cut, considerable deforming and crushing of the cable



Cut performed with a Cable Shear: easy, clean cut without any deformation of the cable



technical change and errors excepted

