

Actuator

18-
081.0052L

Distribution by
Rs-online



<https://rs-online.eao.com/p/18-081.0052L>

Your product:



18-081.0052L Actuator

FRONT

Front dimension:	19 mm x 19 mm
Front form:	Square
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	Flush
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lens colour:	Red
Lens material:	Plastic
Lens illumination:	Illuminated
Lens shape:	Flush
Lens optics:	translucent
Illumination colour:	Red

ELECTRICAL CHARACTERISTICS

Operating voltage:	12 V DC $\pm 10\%$
--------------------	--------------------

MECHANICAL CHARACTERISTIC

Terminal:	Soldering terminal
-----------	--------------------

Weight: 0.003 kg

AMBIENT CONDITION

Operating temperature: – 25 °C ... + 65 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Actuator, 19 mm x 19 mm, Flush, Illuminated, Red, Plastic, translucent, Square, Black, Plastic, Soldering terminal, Red


Dimension: 13.8 mm x 13.8 mm

Product attributes: Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination. The customer has to decide what resistor shall be used to the LED

Wiring diagrams:

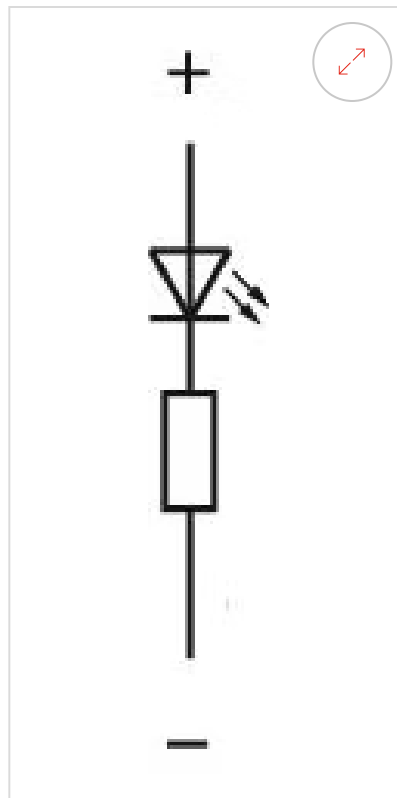


Component layouts:

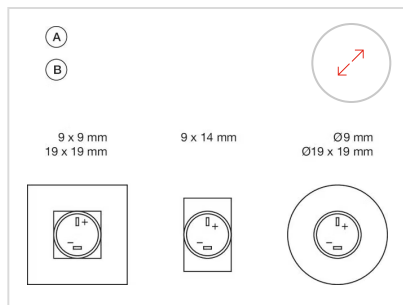

A = Terminals (rear side)
B = Indicator

Mounting cut-outs:

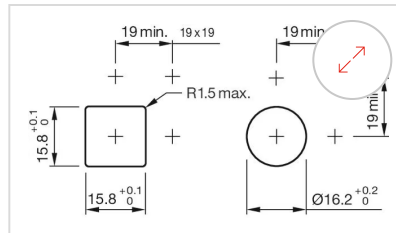

Dimension drawings:

