


# Data sheet



Safety / Valiance RCD Protection

## RCD10WPVN – Valiance White Fused Connection Unit - Passive

### Product Image & Line Diagram

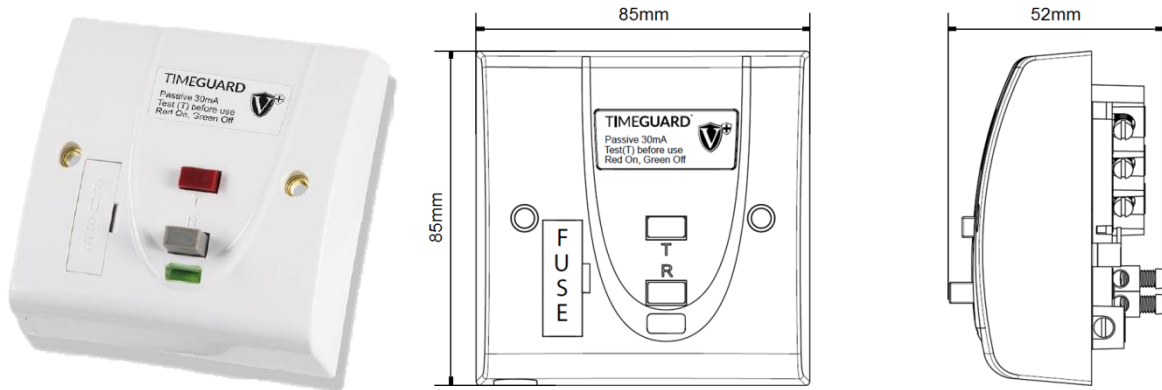

### Technical Data

<b>General</b>	
Operating Voltage	230V AC
Frequency	50Hz
Installation Type	Surface or Recessed
Class Protection	Class 1
Accessories (Included)	Instructions, Fixing Screws x 2
Operating Temperature	-5° to +40°C
Dimensions	Height 85mm, Width 85mm, Depth 52mm
Minimum Box Depth Required	25mm
Weight	139g
Fixed Cable Capacity	1x8mm <sup>2</sup> or 2x4mm <sup>2</sup> or 3x2.5mm <sup>2</sup>
Flexible Cable Capacity	10.5mm Diameter maximum
Altitude	<2000m
EAN	5012483014585
Designed In Accordance To	BS 7288, BS 1363-4 Includes updates & amendments
Guarantee Period	3 Years
<b>RCD Protection</b>	
Classification	Latching (Passive)
RCD Type	Double Pole, Suitable for 2 and 3 wire applications
Rated Trip Current	30mA
Breaking Capacity	250A (Earth leakage)
Trip Speed	Less than 40msec at 150mA residual current
Through Fault Withstand	1500A
<b>Construction</b>	
Body	Thermoset



A theben Group Company

Article Number: RCD10WPVN DS120319V1



Timeguard Ltd reserves the right to withdraw, improve or modify any design without prior notification. Timeguard Ltd cannot be held responsible for the incorrect application of any product.

Additional information can be found at: [www.timeguard.com](http://www.timeguard.com)