


# DRAM MEMORY MODULE SPECIFICATION

- > Lifetime Warranty
- > Delivered in Anti-Static Packaging

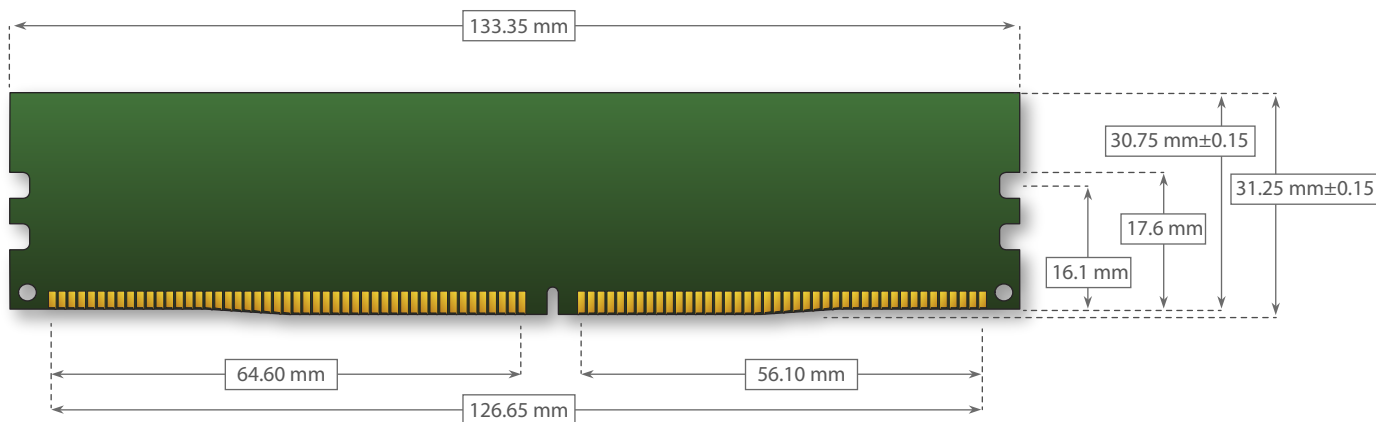

<b>INTEGRAL Part Number</b>	<b>IN4T16GNDLRX</b>
Description	16GB DDR4 2400 MHz DESKTOP NON-ECC MEMORY MODULE
Category	DESKTOP
Form Factor	288pin DIMM
Density	16GB
DRAM Technology	DDR4
Speed	PC4-19200 / 2400 MHz
Depth	2Gbit
Width	X64bit
Buffering	UNBUFFERED
Error Correction	NON-ECC
CAS Latency	17 CYCLES
Voltage	1.2 V
Rank	2
Profile	STANDARD
DRAM IC Configuration	1Gbit X 8bits
DRAM IC Count	16 Chips
DRAM IC Package	FBGA
DRAM IC Placement	DOUBLE SIDED
Note	