

Silhouette® 100 SELV

Axial Bathroom/ Toilet Fans



Features & Benefits

- 17mm stylish ultra low profile grille
- Downstream airflow guide vanes for improved pressure development
- Designed for vertical or horizontal application
- Fan IPX7 rated
- SELV transformer to BSEN 60742
- Indication light
- Suitable for wall, ceiling, panel and window mounting
- Meets current Building Regulations Approved Document F

Slimline Bathroom Ventilation

With a slim profile of only 17mm, Silhouette blends in with the wall surface to provide an unobtrusive installation. Silhouette has a FID performance of 21 l/s. Silhouette can be ceiling/panel mounted and connected to an appropriate duct run to the outside.



17mm actual profile

Models

Silhouette 100SVB

Single speed 100mm bathroom/toilet fan with indication light and back draught shutter.

Stock Ref

439974

Silhouette 100SVT

(Timer)

Single speed 100mm bathroom/toilet fan with integral adjustable electronic overrun timer (5-30 minutes), indication light and back draught shutter.

Stock Ref

439975

Silhouette 100SVH

(Humidity)

Single speed 100mm bathroom/toilet fan with integral adjustable auto humidity sensor from 60-90% RH, indication light and back draught shutter.

Stock Ref

439976

Wall Kit

Stock Ref

254102 (White)

254100 (Brown)

Window kit

Stock ref

442947


Dimensions (mm)

A	BØ	C	D	E	F
160	99	80	97	200	32


Transformer (W X H X D) 147 X 86 X 65

Weight 0.6kg

Panel

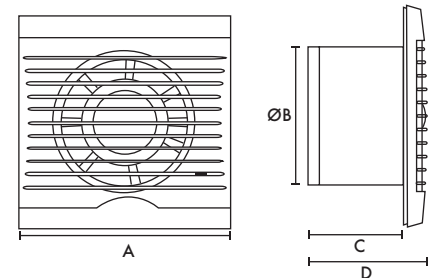

Wall

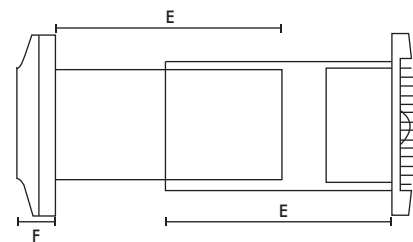

Fixing hole diameter 117mm

Performance

Model	Extract Performance - FID			Sound dB(A)
	m³/h	l/s	Watts	@ 3m
Silhouette 100SVB/SVT/SVH	76	21	15	38