



# PRODUCT DATASHEET

Datasheet creation date: 2025/05/28 7:53 (UTC)



## 22211EAKE4

### Spherical Roller Bearings

#### Parts Number

22211EAKE4C3
--------------

#### Boundary Dimensions

d	55	mm	Bore diameter
D	100	mm	Outside diameter
B	25	mm	Width
r (min.)	1.5	mm	Chamfer dimension

#### Basic Load Ratings

Cr	149000	N	Basic dynamic load rating
C0r	144000	N	Basic static load rating

#### Speeds

Thermal Speed Rating (Oil-bath)	5300	min-1	Oil-bath lubrication subject to conditions outlined in ISO 15312
Mechanical (forced-circulation oil)	9000	min-1	Properly designed and controlled forced-circulation oil lubrication
Grease	5300	min-1	Grease lubrication
Oil (Oil-bath)	6700	min-1	Oil-bath lubrication

#### Abutment and Fillet Dimensions


da (min.)	64	mm	Diameter of shaft abutment
da (max.)	65	mm	Diameter of shaft abutment
Da (min.)	89	mm	Diameter of housing abutment
Da (max.)	91	mm	Diameter of housing abutment
ra (max.)	1.5	mm	Radius of shaft or housing fillet

#### Calculation factors

e	0.23	Constant
Y2	4.3	Axial load Factors
Y3	2.9	Axial load Factors
Y0	2.8	Axial load Factors

#### Mass

Mass approx.	0.81	kg	Mass approx.
--------------	------	----	--------------

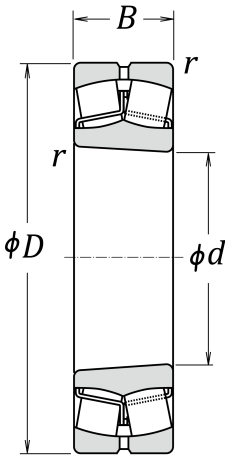

#### Associated products

Adapter	H311X	Adapter
Withdrawal sleeve	AHX311	Withdrawal sleeve