


## Datasheet

# EFNF Series 10A Chassis Mounted Filter

RS Stock number [209-257](#)

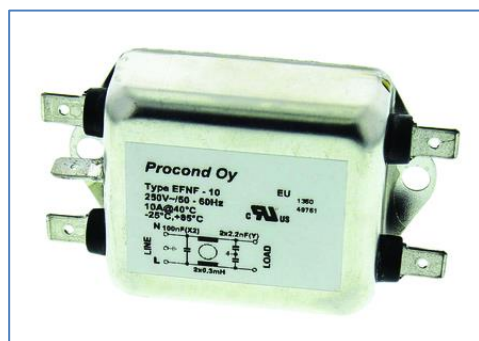

### Description:

Chassis mounting RFI filters providing good attenuation in both differential and common mode over the frequency range 600 KHz to 100MHz

Durable hermetically sealed construction. Ideal for industrial microprocessor-controlled machine systems and other sensitive electronic equipment

Connection is via 250 (1/4 in) terminals suitable for soldering or push-on receptacles (see Connectors/Terminals section)

### Specification:

- Depth: 75mm
- Dimensions: 46 x 75 x 19mm
- Height: 19mm
- Length: 46mm
- Maximum Current Rating: 10A
- Maximum Operating Temperature: +85°C
- Maximum Voltage Rating : 250 V ac
- Minimum Operating Temperature: -25°C
- Mounting Type: Chassis Mount
- Operating Frequency: 400Hz
- Series: EFNF
- Termination Style: Tab

### Dimensions (mm):

