


Geberit Mapress Copper adaptor union with female thread

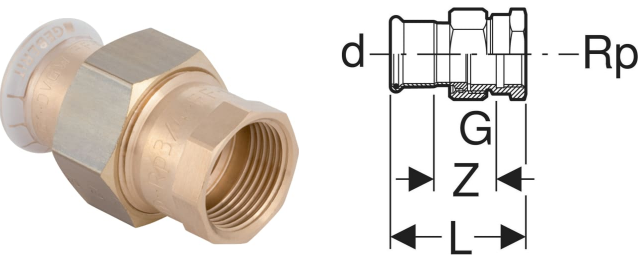

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For compressed air (oil purity class 0–3)
- For negative pressure

- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Union nut made of brass
- Seal ring made of CIIR, black

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	Gunmetal / lead-free gunmetal

Art. no.	DN	d, ø mm	Rp "	G "	Product material	L cm	Z cm
65481	10 / 15	12	1/2	1/2	Gunmetal	5.2	2.2
65482	12 / 15	15	1/2	3/4	Lead-free gunmetal	5	1.7
65490	12 / 20	15	3/4	3/4	Lead-free gunmetal	5.9	2.4
65483	15	18	1/2	3/4	Lead-free gunmetal	5	1.7

Art. no.	DN	d _ø mm	R _p "	G "	Product material	L cm	Z cm
65491	15 / 20	18	3/4	3/4	Lead-free gunmetal	5.9	2.4
65484	20	22	3/4	1	Gunmetal	6.2	2.6
65492	20 / 25	22	1	1	Gunmetal	6.6	2.8
65485	25	28	1	1 1/4	Lead-free gunmetal	6.3	2.3
65486	32	35	1 1/4	1 1/2	Lead-free gunmetal	7.5	3
65487	40	42	1 1/2	1 3/4	Lead-free gunmetal	7.9	3
65488	50	54	2	2 3/8	Gunmetal	8.5	2.7