


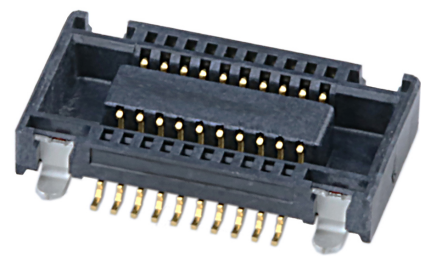

Part Number : [543630289](#)
Product Description : 0.50mm Pitch SlimStack Receptacle, Surface Mount, Dual Row, Vertical, 2.00mm Stacking Height, with Solder Tabs, 20 Circuits
Series Number : 54363
Status : Active
Product Category : Board-to-Board Connectors



Documents & Resources


Drawings
[543630289_sd.pdf](#)

3D Models and Design Files
[543630289_stp.zip](#)

Specifications
[543639200-SPK-200.pdf](#)
[PS-54363-046-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

- Multiple Part Product Compliance Statements
- Eu RoHS
 - REACH SVHC
 - Low-Halogen

- Multiple Part Industry Compliance Documents
- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Board-to-Board Connectors
Series	54363
Description	0.50mm Pitch SlimStack Receptacle, Surface Mount, Dual Row, Vertical, 2.00mm Stacking Height, with Solder Tabs, 20 Circuits
Series Name	0.5, BB H2
Application	Board-to-Board, Signal
Component Type	PCB Receptacle
Product Name	SlimStack
UPC	822348323906

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V AC (RMS)/DC

Physical

Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Mated Height	2.00mm
Mated Width	6.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold

Material - Resin	High Temperature Thermoplastic
Net Weight	94.821/mg
Number of Rows	2
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Retention	Yes
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.254µm
Plating min - Termination	0.051µm
Polarized to Mating Part	No
Polarized to PCB	No
Temperature Range - Operating	-40° to +105°C
Termination Interface Style	Surface Mount

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.50mm Pitch Vertical SlimStack Plugs	<u>55650</u>