


1259495 DHDS-50-A Three-point gripper - Series: All

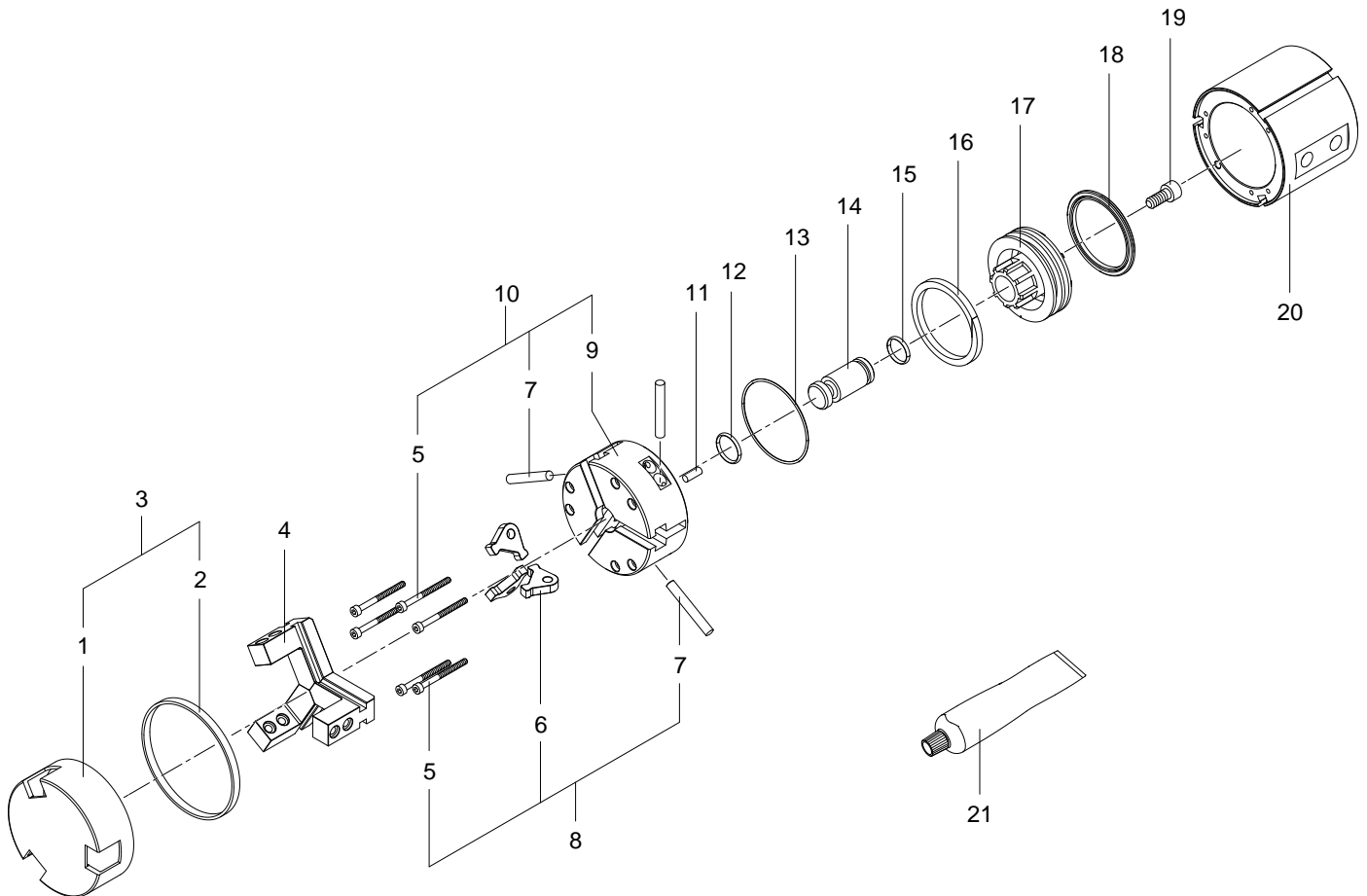

1259495 DHDS-50-A Three-point gripper - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	1567957	DHDS-50-A Set of wearing parts		1	PC
1			Not available separately, see position 3	1	PC
2			Not available separately, see position 3	1	PC
3	1567956	DHDS-50-A Covering		1	PC
4	1567954	DHDS-50-A Gripper jaw		1	PC
5			Not available separately, see position 8+10+998	6	PC
6			Not available separately, see position 8	3	PC
7			Not available separately, see position 8+10+998	3	PC
8	1567953	DHDS-50-A Reversing lever		1	PC
9			Not available separately, see position 10	1	PC
10	1567955	DHDS-50-A Jaw guide		1	PC
11			Not available	1	PC
12			Not available separately, see position 998+999 Grease using during assembly. See position 21	1	PC
13			Not available separately, see position 998+999 Grease using during assembly. See position 21	1	PC
14			Not available separately, see position 998	1	PC
15			Not available separately, see position 998+999 Grease using during assembly. See position 21	1	PC
16			Not available separately, see position 998	1	PC
17			Not available separately, see position 998	1	PC
18			Not available separately, see position 998+999 Grease using during assembly. See position 21	1	PC
19			Not available separately, see position 998	1	PC
20			Not available	1	PC
21	397394	LUB-M1-SILIKONFREI-10ML Lubricating grease		1	PC
99 8	1567952	DHDS-50-A Piston module		1	PC