


Section 7: Floor to Frame Elements

Casters

Heavy-Duty Casters

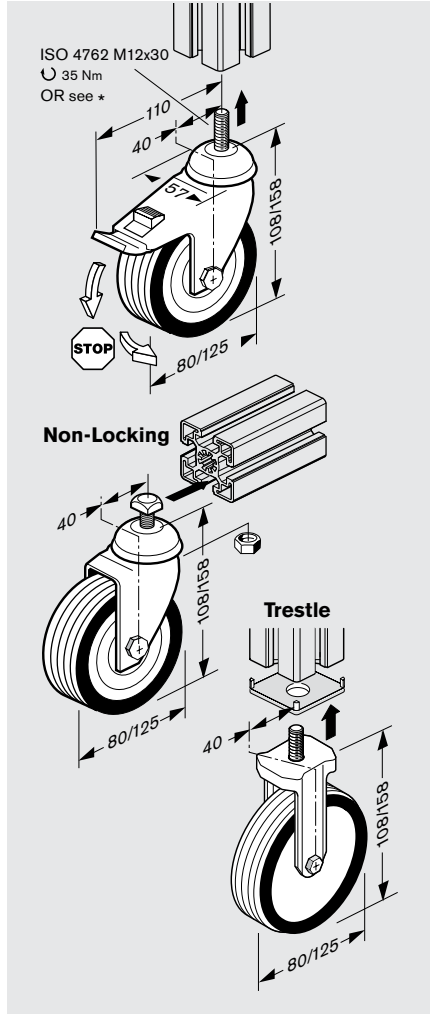


Features:

- Suitable for tool carts and small machines that must be transported from one area to another
- Available in locking or non-locking versions
- Standard width 32mm
- Four types are available:
 - 1 Conductive for ESD applications
 - 2 Chemical-resistant, reinforced wheels (resistant to petroleum and alcohol based solvents)
 - 3 Floor-protective to prevent marring of floor surfaces
 - 4 Solid core abrasion-resistant, which are suitable for ESD and clean room applications
- Types 1, 3 and 4 are available with 80mm or 125mm diameter wheels
- Type 2 is available with 125mm diameter wheels only

Material:

- Types 1 TPE with thread pick-up protection
- Type 2: polyamide reinforced
- Type 3: TPE on polyamide rim
- Type 4: TPE or solid rubber

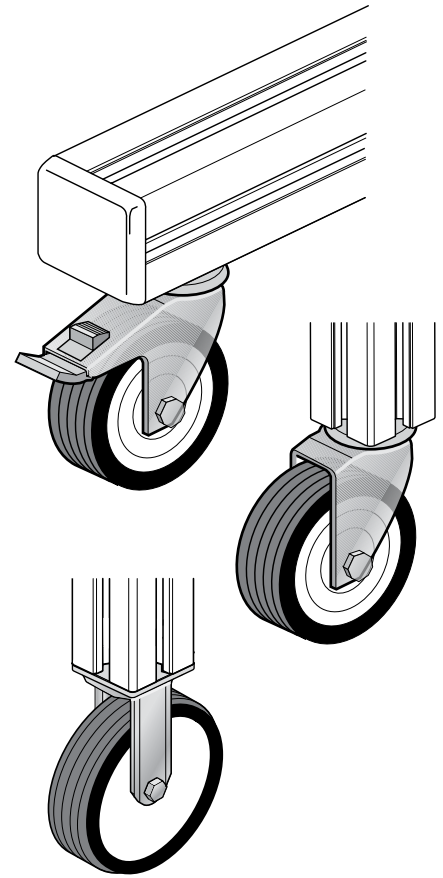

Caster Type	Max. Load in N (lbs.)	
	80mm wheel	125mm wheel
1	900 (202)	1100 (247)
2	N/A	1100 (247)
3	900 (202)	1100 (247)
4	900 (202)	1100 (247)

Description	Lot Size	Part Number
1 Locking heavy-duty caster, 80mm, conductive	1	3 842 541 230
1 Non-locking heavy-duty caster, 80mm, conductive	1	3 842 541 238
1 Locking heavy-duty caster, 125mm, conductive	1	3 842 541 232
1 Non-locking heavy-duty caster, 125mm, conductive	1	3 842 541 240
2 Locking heavy-duty caster, 125mm, chemical-resistant	1	3 842 515 367
2 Non-locking heavy-duty caster, 125mm, chemical-resistant	1	3 842 515 366
3 Locking heavy-duty caster, 80mm, floor-protective	1	3 842 541 226
3 Non-locking heavy-duty caster, 80mm, floor-protective	1	3 842 541 234
3 Locking heavy-duty caster, 125mm, floor-protective	1	3 842 541 228
3 Non-locking heavy-duty caster, 125mm, floor-protective	1	3 842 541 236
4 Locking heavy-duty caster, 125mm, solid core abrasion resistant	1	3 842 524 499
4 Non-locking heavy-duty caster, 125mm, solid core abrasion resistant	1	3 842 524 500
4 Heavy-duty Trestle caster, 80mm, solid core abrasion resistant	1	3 842 541 242
4 Heavy-duty Trestle caster, 125mm, solid core abrasion resistant	1	3 842 541 244
* M12 Hex Screw (alternate caster connector)	1	2 911 061 911

GoTo boschrexroth-us.com/framing to get these in stock items **FAST** from your local distributor