

Features

- 3/4" (DN20)
- Working Pressure: 2 ~ 20 kgf/cm²
- Working Temp: -45°C ~ 185°C
- Material: CAST BRONZE
- Spring material SS 316
- Gasket material PTFE

RS PRO Safety Valves


RS Stock No.: 0336757



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- These Safety Valves are mainly suitable for boilers, pressure vessels, steam generators or gas pipelines.
- The products are used for working noncorrosive fluid such as natural gas, air, and steam.
- Working Temperature: $-45^{\circ}\text{C} \sim 185^{\circ}\text{C}$
- Working Pressure: $2 \sim 10 \text{ kgf/cm}^2$ or $11 \sim 20 \text{ kgf/cm}^2$

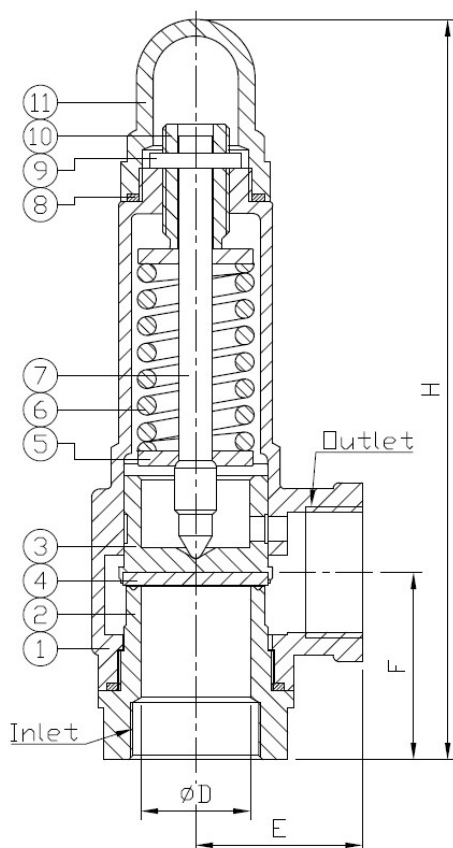

SIZE	Inlet	Outlet	D	E	F	H	Lift
1/2"	1/2"	1/2"	13	29	45.5	139	0.52
3/4"	3/4"	3/4"	19	36	49	159	0.76

SIZE	Inlet	Outlet	D	E	F	H	Lift
1"	1"	1"	25	40	55	188	1

unit:mm

ITEM	PARTS	MATERIAL
1	BODY	CAST BRONZE
2	VALVE SEAT	BRASS
3	DISC	
4	SEAL	PTFE
5	SPRING SEAT	BRASS
6	SPRING	STEEL
7	STEM	BRASS
8	GASKET	PTFE
9	LOCK NUT	BRASS
10	ADJUST SCREW	
11	CAP	