




Connectors > Connector Accessories > Connector Hardware

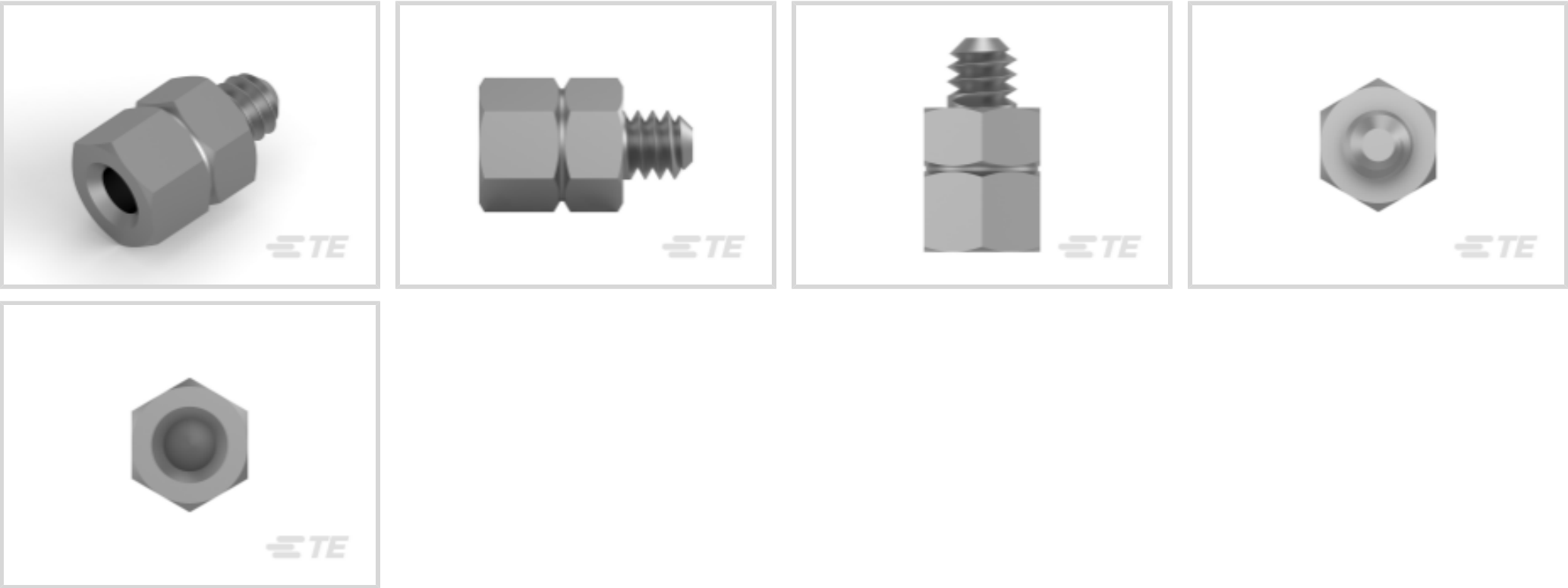

Connector Hardware Accessory Type: **Female Screwlock**
Hardware Accessory Function: **Latching, Locking & Retention**

Features

Product Type Features

Connector Hardware Accessory Type	Female Screwlock
Hardware Accessory Function	Latching, Locking & Retention

Mechanical Attachment

Thread Size	4-40 UNC 2A (Male), 4-40 UNC 2B (Female)
-------------	--

Dimensions

Thread Length	3 mm[.118 in]
Product Feature Length	9.2 mm[.36 in]

Packaging Features

Packaging Method	Carton
Packaging Quantity	2000

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247)



Candidate List Declared Against: JUNE 2024 (241)
SVHC > Threshold:
Pb (3.5% in Component Part)

Article Safe Usage Statements:
Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 3-828102-2

[HD-20SCHRAUB-SICHRG](#)

Also in the Series | [AMPLIMITE Kit](#)


Connector Caps & Covers(2)

Connector Hardware(91)


Connector Seals & Cavity Plugs(4)

Connector Strain Relief(126)


Customers Also Bought

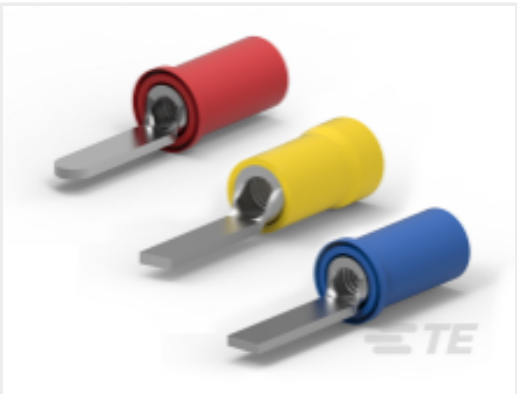


TE Part #CAT-P592-T116
PIDG Pre-Insulated Diamond Grip Tabs

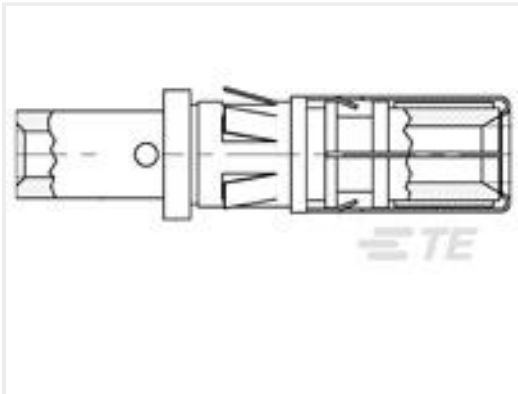

TE Part #202417-1
SKT CONT ASSY,TYPE I

 

TE Part #5038924001
DCPT-8/4-45-SP

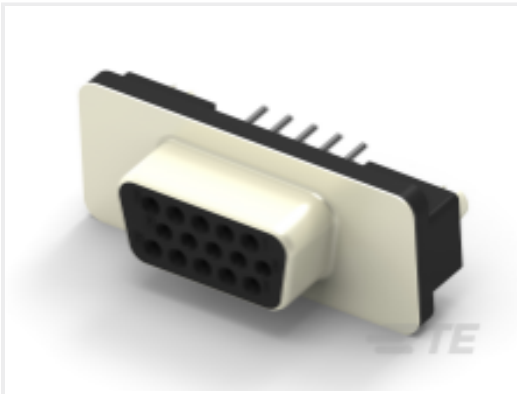

TE Part #2317171-1
AMPL REC, HD22, VERT, 15P, THREADED



TE Part #678853-000
CWT-7



 
TE Part #86BSD015PG-3AIC
15 PSIG 14 BIT DIGITAL PRESSURE SENSOR



TE Part #2-1623714-8
FCB4 4R7 5% HP



TE Part #1-6609016-7
10ED1C=F7433 S0



TE Part #86BSD200PA-3AKC
PRESS,ISO,BACK-SIDE DIGITAL

Documents

Product Drawings
HD-20SCHRAUB-SICHRG

English

CAD Files
3D PDF

3D

Customer View Model
ENG_CVM_CVM_3-828102-1_J.2d_dxf.zip

English

Customer View Model
ENG_CVM_CVM_3-828102-1_J.3d_igs.zip

English

Customer View Model
ENG_CVM_CVM_3-828102-1_J.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.